


# E21010



## Cable gland

CABLE GLAND M20 SKINTOP

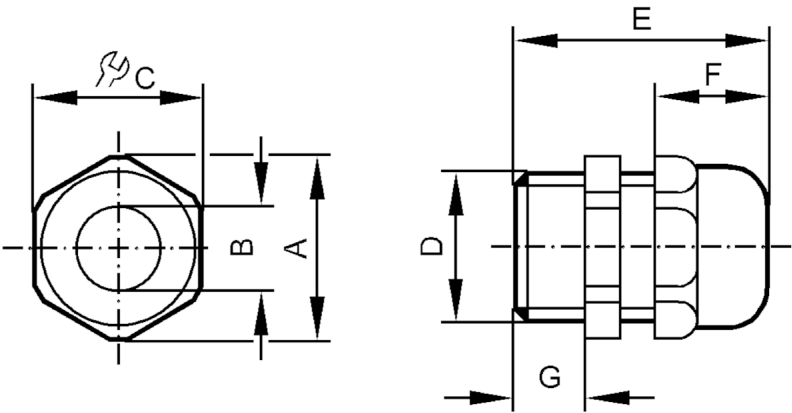

|   |           |
|---|-----------|
| A | 28        |
| B | 5...10    |
| C | 25        |
| D | M20 x 1.5 |
| E | 38        |
| F | 17        |

### Operating conditions

|                     |      |           |
|---------------------|------|-----------|
| Ambient temperature | [°C] | -25...100 |
|---------------------|------|-----------|

### Mechanical data

|                    |      |                                |
|--------------------|------|--------------------------------|
| Weight             | [g]  | 12.2                           |
| Dimensions         | [mm] | M20 x 1.5                      |
| Thread designation |      | M20 x 1.5                      |
| Materials          |      | housing: PA black; Sealing: CR |
| Length             | [mm] | 38                             |

### Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|