




Fibre optic diffuse reflection sensor

FT-11-M-V-M6/1,2M

Article no longer available - archive entry

Alternative articles: E21038

When selecting an alternative article and accessories please note that technical data may differ!

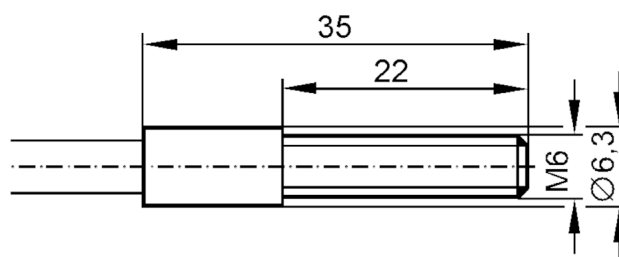

Application

Function principle	Diffuse reflection sensor
--------------------	---------------------------

Detection zone

Range with fibre optic amplifier type	OB5030
---------------------------------------	--------

OB50

Range fibre optics [mm]	35
-------------------------	----

Operating conditions

Ambient temperature [°C]	-20...150
--------------------------	-----------

Mechanical data

Version of sensing head	straight
Sensing head thread	M6
Total length [mm]	1200
Min. bending radius [mm]	20
Fibre material	glass
Fibre head material	stainless steel (1.4305 / 303)
Fibre sheath material	metal silicone

Remarks

Pack quantity	1 pcs.
---------------	--------