




Welding thermowell for temperature sensors

THERMOWELL, D6/WELD-IN/L=230

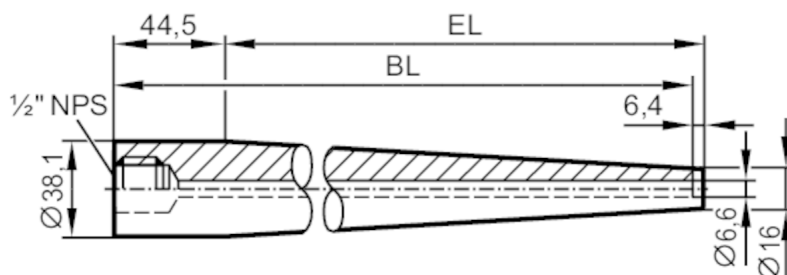

EC 1935/2004 EHEDG Certified



Application

Design for temperature sensors EL = 300 mm

Pressure rating [bar] 400

Accuracy / deviations

Max. permissible flow velocity [m/s] 25

Mechanical data

Weight [g] 1236

Materials stainless steel (316L/1.4404)

Sensor connection 1/2" NPS Ø 6 mm suitable for G1/2 and 1/2" NPT

Process connection welding adapter Ø 38,1 mm

Installation length EL [mm] 191

Bore length BL [mm] 228.6

Remarks

Pack quantity 1 pcs.