


E60146



Wirable socket

SDOGK210MKRFKSG

Article no longer available - archive entry

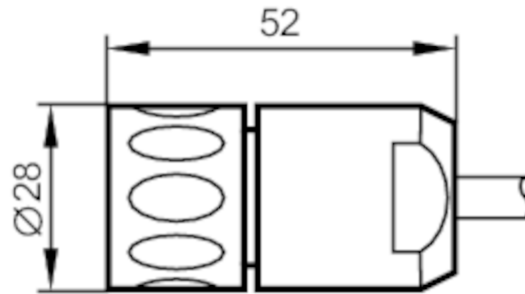

Electrical data

Operating voltage [V] 4.5...30 DC

Operating conditions

Ambient temperature [°C] -40...125

Protection IP 67

Mechanical data

Weight [g] 68.8

Dimensions [mm] 28 x 28 x 52

Materials brass in plastic sheath; PA 6.6 black

Moulded-body material brass / PA 6.6, in plastic sheath / brass / PA 6.6, in plastic sheath

Material nut brass, in plastic sheath / PA 6.6, in plastic sheath

Remarks

Pack quantity 1 pcs.

Electrical connection

soldering/crimping connection: ...0.5 mm²

Electrical connection - socket

Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, in plastic sheath; Locking: brass, in plastic sheath


Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, in plastic sheath; Locking: PA 6.6, in plastic sheath

E60146



Wirable socket

SDOGK210MKRFKSG

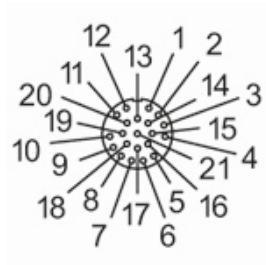

Connection

- 1 _____
- 2 _____
- 3 _____
- 4 _____
- 5 _____
- 6 _____
- 7 _____
- 8 _____
- 9 _____
- 10 _____
- 11 _____
- 12 _____
- 13 _____
- 14 _____
- 15 _____
- 16 _____
- 17 _____
- 18 _____
- 19 _____
- 20 _____
- 21 _____