




## Push-in T-fitting for pneumatic connections

AirBox push-in T-connect 10pcs

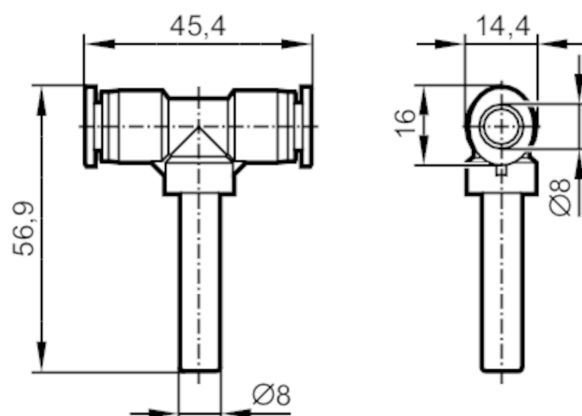

### Application

Media	compressed air according to ISO 8573-1: 2001
-------	--

### Operating conditions

Operating pressure	[bar]	10; (min. -0,95)
Ambient temperature	[°C]	-20...80

### Mechanical data

Weight	[g]	120.1
Materials	housing: nickel-plated brass / PA66; release ring: polyoxymethylene; Tooth lock washer: stainless steel; form ring: NBR	
Tube fittings	8 mm	
Sleeve diameter	[mm]	8

### Remarks

Pack quantity	10 pcs.
---------------	---------