


ZDO6H057MSS0010H09




yes

-5...60

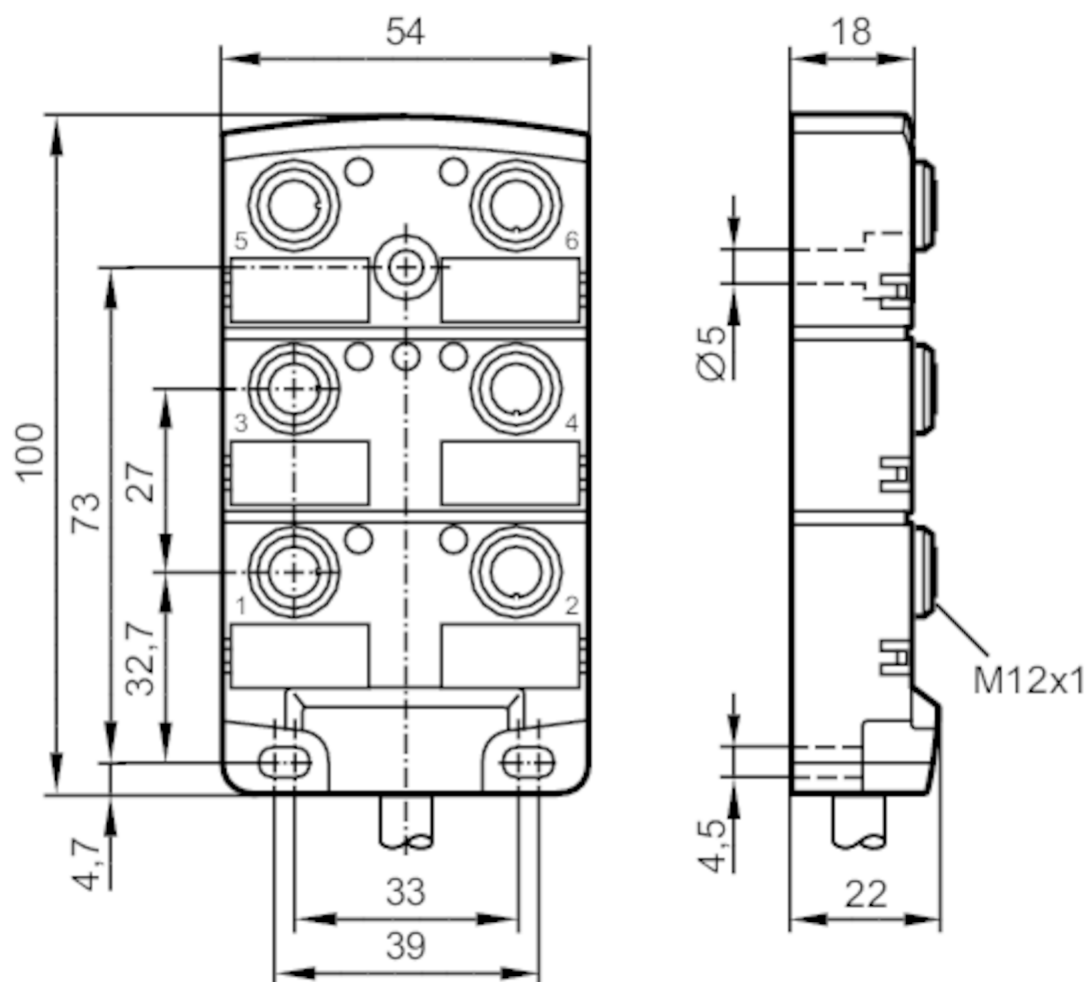

Splitter box

ZDO6H057MSS0010H09

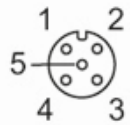
Protection	IP 67; IP 68	
Mechanical data		
Weight	[g]	1034
Dimensions	[mm]	22 x 54 x 100
Materials	PA	
Moulded-body material	PA	
Number of ports splitter box	6	
Connector type	M12	
Drag chain suitability	yes	
Drag chain suitability	bending radius for flexible use	min. 10 x cable diameter
	bending cycles	> 2 Mio.
Displays / operating elements		
Display	switching status	6 x LED, yellow
	operation	1 x LED, green
Accessories		
Items supplied	Protective caps: 2	
	labels: 6	
Remarks		
Pack quantity	1 pcs.	
Electrical connection		
Cable: 10 m, PUR, Halogen-free, black, Ø 7.8 mm; 6 x 0.34 mm² (43 x Ø 0.1 mm) + 3 x 1 mm² (55 x Ø 0.15 mm)		
Electrical connection - slot		
Connector: 6 x M12; coding: A; Moulded body: PA; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm		
		



Splitter box

ZDO6H057MSS0010H09

Connection

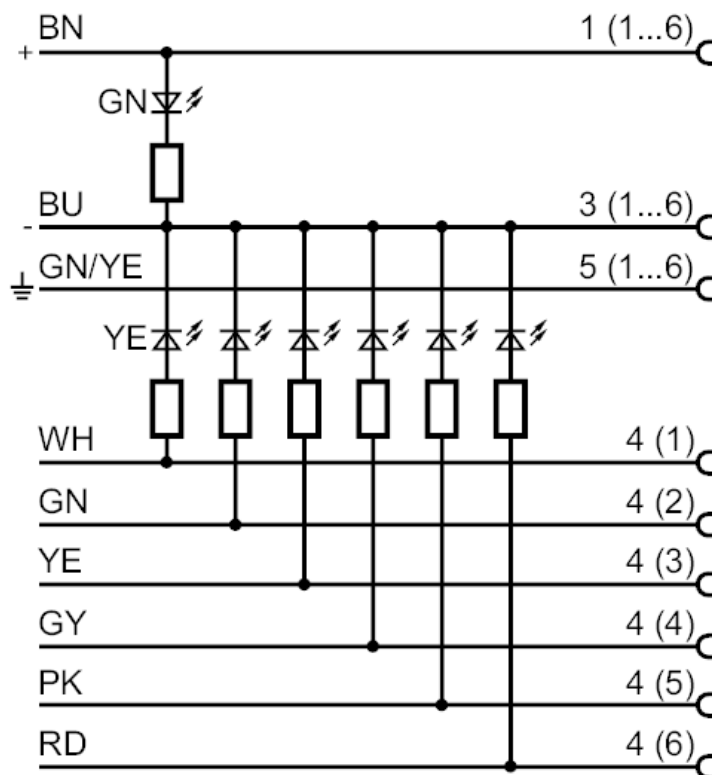

BN =	Core colours :	brown
BU =		blue
GN =		green
GN/YE =		green/yellow
GY =		grey
PK =		pink
RD =		red
WH =		white
YE =		yellow