


## Connecting cable with socket

ADOGF030SCS0005T03

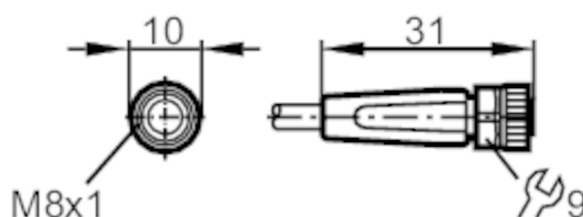

## Application

Special feature	Free from silicone; Halogen-free; Gold-plated contacts; Drag chain suitability
Application	welding applications
Free from silicone	yes

## Electrical data

Operating voltage [V]	< 50 AC / < 60 DC
Protection class	III
Max. current load total [A]	3

## Operating conditions

Ambient temperature [°C]	-25...90
Note on ambient temperature	cULus: ...85 °C
Ambient temperature (moving) [°C]	-25...90
Note on ambient temperature (moving)	cULus: ...85 °C
Protection	IP 65; IP 67; IP 68; IP 69K

## Mechanical data

Weight [g]	136.8
Dimensions [mm]	10 x 10 x 31
Materials	housing: TPU orange; Sealing: FKM
Material nut	brass, anti-spatter
Drag chain suitability	yes

# EVW069



## Connecting cable with socket

ADOGF030SCS0005T03

Drag chain suitability	bending radius for flexible use	min. 10 x cable diameter
	travel speed	max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s <sup>2</sup>
	bending cycles	> 2 Mio.
	torsional strain	± 180 °/m

### Remarks

Pack quantity 1 pcs.

### Electrical connection


Cable: 5 m, PUR, Halogen-free, grey, Ø 4.5 mm; not irradiated (can be recycled); resistant to welding sparks; 3 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Locking: brass, anti-spatter; Contacts: gold-plated; Tightening torque: 0.3...0.5 Nm



### Connection

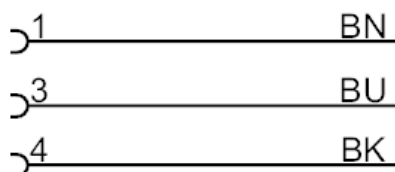

BK = Core colours :  
black  
BN = brown  
BU = blue