


L31000




Connecting cable with socket

ADOGB030ALS0002X03

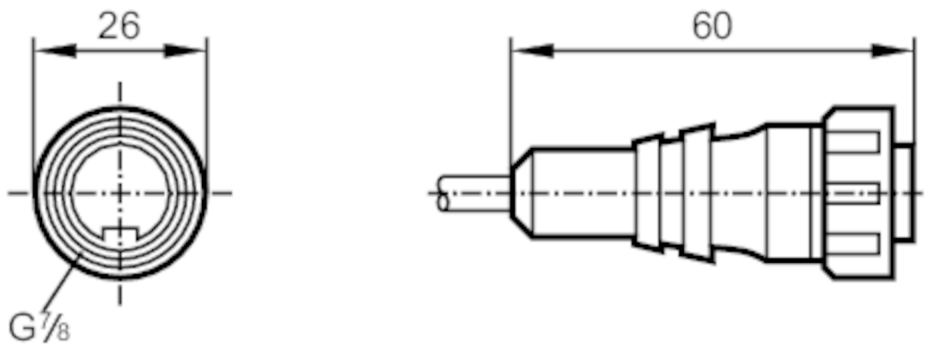

Electrical data		
Operating voltage	[V]	< 600 DC
Operating conditions		
Ambient temperature	[°C]	-40...90
Protection		IP 68
Mechanical data		
Weight	[g]	281.227
Dimensions	[mm]	26 x 26 x 60
Materials		TPU
Moulded-body material		TPU
Material nut		TPU
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 2 m, PVC, orange, Ø 10 mm; 3 x 1.5 mm² / AWG 16		
Electrical connection - socket		
Connector: 1 x 7/8", straight; coding: A; Moulded body: TPU; Locking: TPU		

 


L31000



Connecting cable with socket

ADOGB030ALS0002X03

Connection

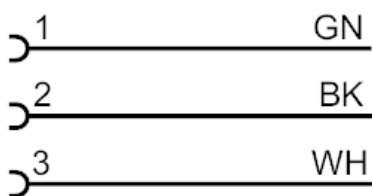

BK =	Core colours :	black
GN =		green
WH =		white