


L33600



Wirable plug

SSTGF030MSSFKPG

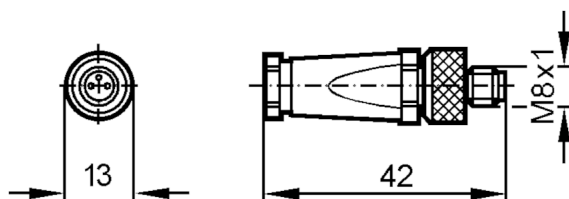

Application

Special feature	Gold-plated contacts
-----------------	----------------------

Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Weight	[g]	22.68
Dimensions	[mm]	13 x 13 x 42
Materials		brass nickel-plated
Moulded-body material		brass, nickel-plated
Material nut		brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

L33600



Wirable plug

SSTGF030MSSFKPG

Electrical connection

soldering: ...0.34 mm²; Cable sheath: Ø 3.5...5 mm

Electrical connection - plug

Connector: 1 x M8, straight; coding: A; Moulded body: brass, nickel-plated; Locking: brass, nickel-plated; Contacts: gold-plated



Connection

