


# L34103



## Wirable socket

SDOAA030MSSFKPG

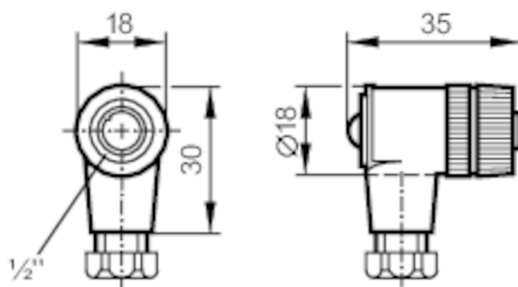

### Application

Special feature

Gold-plated contacts

### Electrical data

Operating voltage

[V]

< 250 AC

Max. current load total

[A]

4; (...40 °C)

### Operating conditions

Ambient temperature

[°C]

-25...90

Protection

IP 67

### Mechanical data

Weight

[g]

27.216

Dimensions

[mm]

35 x 20 x 30

Materials

PA

Moulded-body material

PA

Material nut

brass, nickel-plated

### Remarks

Pack quantity

1 pcs.

# L34103



## Wirable socket

SDOAA030MSSFKPG

### Electrical connection

terminals: ...0.75 mm<sup>2</sup>; Cable sheath: Ø 4...6 mm

### Electrical connection - socket

Connector: 1 x 1/2", angled; coding: C; Moulded body: PA; Locking: brass, nickel-plated; Contacts: gold-plated



### Connection

