


L34107



Wirable socket

SDOAA030MSSFKPG

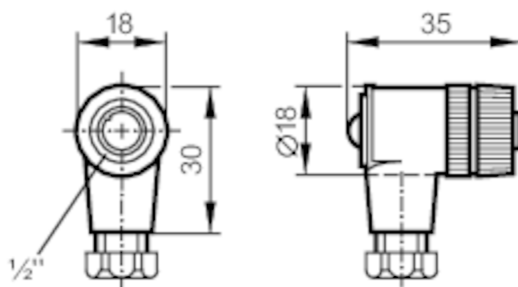

Application

Special feature

Gold-plated contacts

Electrical data

Operating voltage

[V]

< 250 AC

Max. current load total

[A]

4; (...40 °C)

Operating conditions

Ambient temperature

[°C]

-25...90

Protection

IP 67

Mechanical data

Weight

[g]

27.216

Dimensions

[mm]

35 x 20 x 30

Materials

PA

Moulded-body material

PA

Material nut

brass, nickel-plated

Remarks

Pack quantity

1 pcs.

L34107



Wirable socket

SDOAA030MSSFKPG

Electrical connection

terminals: ...0.75 mm²; Cable sheath: Ø 6...8 mm

Electrical connection - socket

Connector: 1 x 1/2", angled; coding: C; Moulded body: PA; Locking: brass, nickel-plated; Contacts: gold-plated



Connection

