


L34112



Wirable plug

SSTGB030ALSFKPG

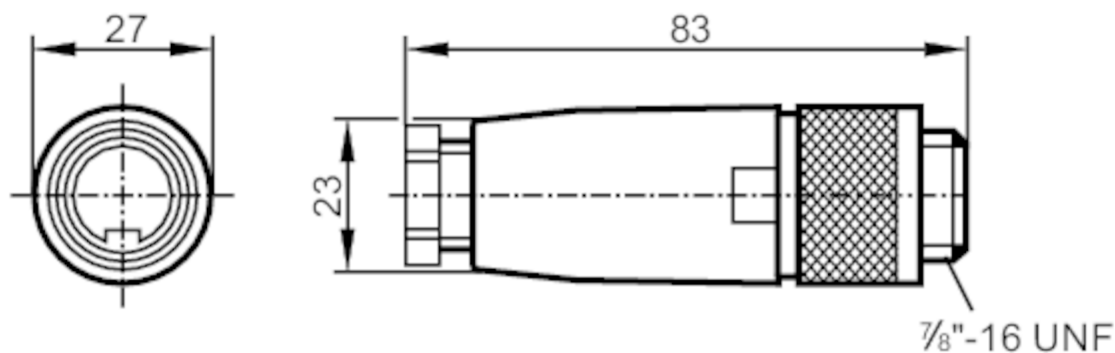

Electrical data

Operating voltage	[V]	< 600 AC
Max. current load total	[A]	12

Operating conditions

Ambient temperature	[°C]	-40...90
Protection		IP 67

Mechanical data

Weight	[g]	45.359
Dimensions	[mm]	27 x 27 x 83
Materials		PA 6.6
Moulded-body material		PA 6.6
Material nut		aluminium, black anodised

Remarks

Remarks	pin 2 leading
Pack quantity	1 pcs.

L34112



Wirable plug

SSTGB030ALSFKPG

Electrical connection

terminals: ...1.5 mm²; Cable sheath: Ø 6...8 mm

Electrical connection - plug

Connector: 1 x 7/8", straight; coding: A; Moulded body: PA 6.6; Locking: aluminium, black anodised



Connection

