


# L34115



## Wirable socket

SDOGB030ALSFKPG

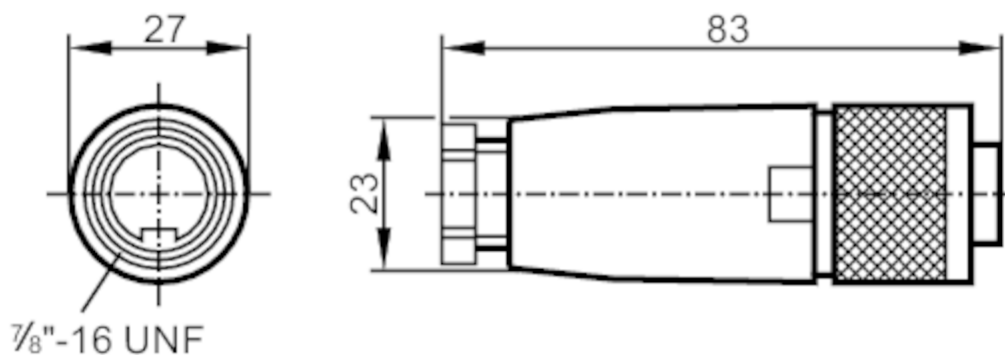

### Electrical data

|                         |     |          |
|-------------------------|-----|----------|
| Operating voltage       | [V] | < 600 AC |
| Max. current load total | [A] | 12       |

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -40...90 |
| Protection          |      | IP 67    |

### Mechanical data

|                       |      |                           |
|-----------------------|------|---------------------------|
| Weight                | [g]  | 45.359                    |
| Dimensions            | [mm] | 27 x 27 x 83              |
| Materials             |      | PA 6.6                    |
| Moulded-body material |      | PA 6.6                    |
| Material nut          |      | aluminium, black anodised |

### Remarks

|               |               |
|---------------|---------------|
| Remarks       | pin 2 leading |
| Pack quantity | 1 pcs.        |

# L34115



## Wirable socket

 
SDOGB030ALSFKPG

### Electrical connection

terminals: ...1.5 mm<sup>2</sup>; Cable sheath: Ø 5...13 mm

### Electrical connection - socket

Connector: 1 x 7/8", straight; coding: A; Moulded body: PA 6.6; Locking: aluminium, black anodised



### Connection

