


L35040



Adapter socket

RDOGF030MSS00.5-03

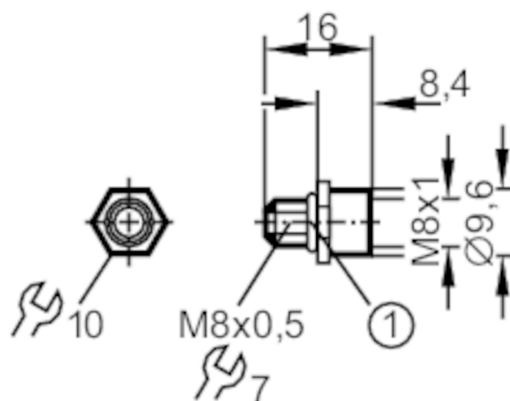

1 O-ring

Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...80
Protection		IP 67

Mechanical data

Weight	[g]	1.361
Mounting thread		M8
Materials		brass nickel-plated
Moulded-body material		brass, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

L35040



Adapter socket

 
RDOGF030MSS00.5-03

Electrical connection


Cable: 0.15 m, PVC; 2 x 0.34 mm²

Electrical connection - socket

Connector: 1 x M8; coding: A; Moulded body: brass, nickel-plated



Connection

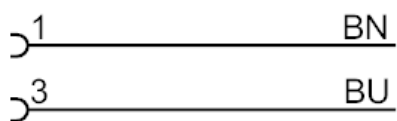

BN = Core colours :
BU = brown
 blue