


Y connection cable

YDOGH040MSS0001B03STGH040MSS

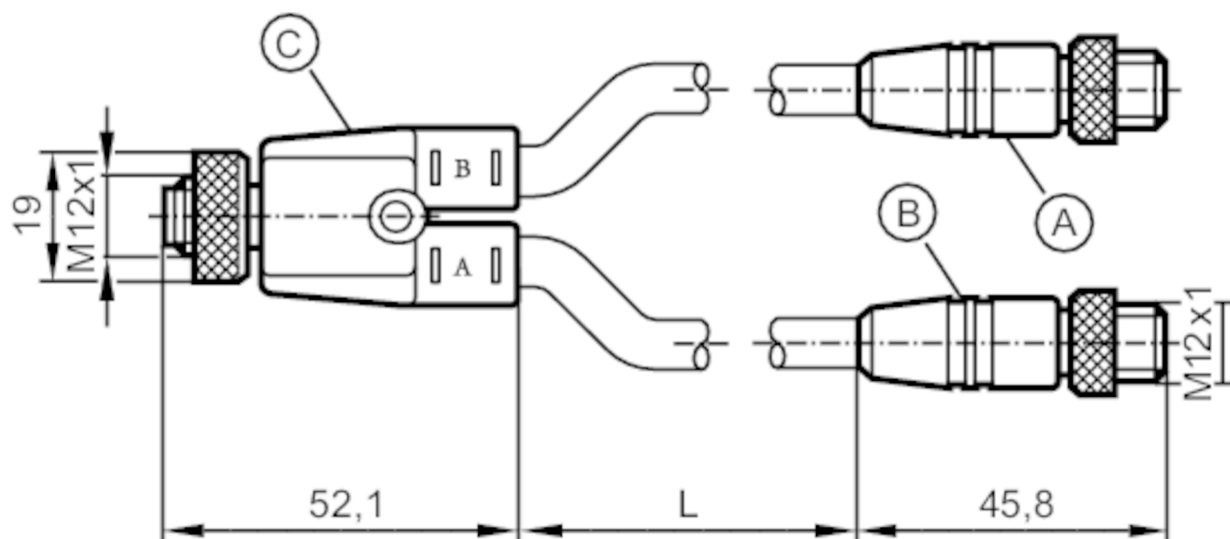

Electrical data

Operating voltage	[V]	< 250 AC / < 300 DC
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-40...90
Protection		IP 68

Mechanical data

Weight	[g]	22.68
Materials		PUR
Moulded-body material		PUR
Material nut		brass, nickel-plated
Number of ports splitter box		2

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 1 m, PUR, yellow, Ø 5.842 mm; 3 x 0.75 mm² / AWG 18

Electrical connection - plug

Connector: 2 x M12; coding: A; Moulded body: PUR; Locking: brass, nickel-plated



L44220




Y connection cable

YDOGH040MSS0001B03STGH040MSS

Electrical connection - socket

Connector: 2 x M12; coding: A; Moulded body: PUR; Locking: brass, nickel-plated

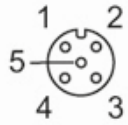

Connection

