


Temperature cable sensor with screw-in sensor

TS-500KLKM...

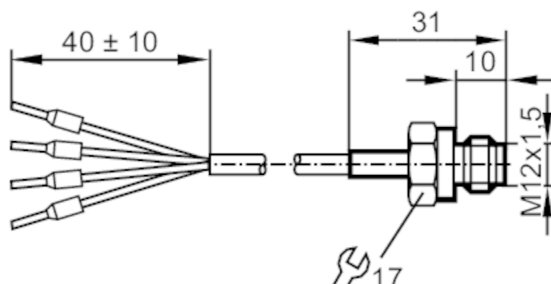

Product characteristics

Measuring range	-30...150 °C	-22...302 °F
Process connection	threaded connection M12 x 1,5 external thread	

Application

Measuring element	1 x Pt 100; (to DIN EN 60751, class A)	
Installation	surface mount RTD for solid bodies	
Pressure rating [bar]	500	

Electrical data

Protection class	III	
------------------	-----	--

Measuring/setting range

Measuring range	-30...150 °C	-22...302 °F
-----------------	--------------	--------------

Accuracy / deviations

Accuracy [K]	$\pm (0,15 \text{ K} + 0,002 \times t)$	
--------------	---	--

Response times

Dynamic response T05 / T09 [s]	4 / 12; (to DIN EN 60751)	
--------------------------------	---------------------------	--

Operating conditions

Protection	IP 67	
------------	-------	--

Tests / approvals

MTTF [years]	12683.9	
--------------	---------	--

Mechanical data

Weight [g]	214.2	
Housing	screw-in sensor	
Dimensions [mm]	M12 x 1.5 / L = 31	
Thread designation	M12 x 1.5	
Materials	stainless steel (304/1.4301)	
Process connection	threaded connection M12 x 1,5 external thread	

Remarks

Pack quantity	1 pcs.	
---------------	--------	--

TS5951




Temperature cable sensor with screw-in sensor

TS-500KLKM...

Electrical connection

Cable: 5 m, silicone; with wire end ferrules

Connection

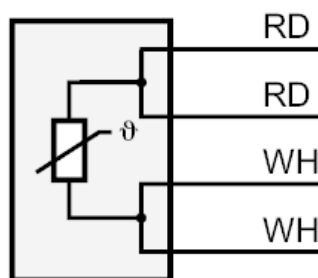

RD =

WH =

Core colours :

red

white