


Adapter plug

RSTGH040ALS00.3-04

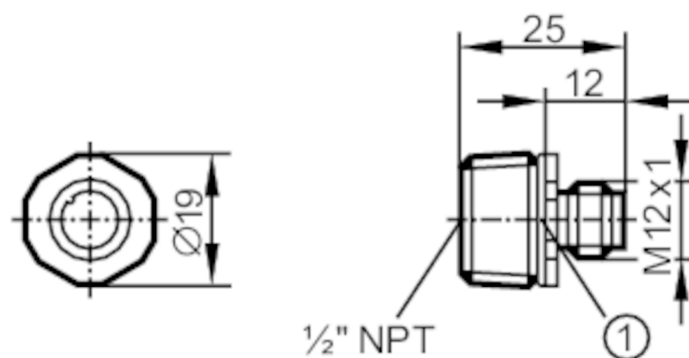

1 O-ring

Electrical data

Operating voltage	[V]	< 250 DC
-------------------	-----	----------

Operating conditions

Ambient temperature	[°C]	-20...90
---------------------	------	----------

Mechanical data

Weight	[g]	22.68
Mounting thread		1/2" NPT
Materials		aluminium anodised 10...20 µm
Moulded-body material		aluminium, anodised 10...20 µm

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 0.5 m, PVC; 4 x 0.34 mm² / AWG 22

Electrical connection - plug

Connector: 1 x M12; coding: A; Moulded body: aluminium, anodised 10...20 µm



W10114



Adapter plug

RSTGH040ALS00.3-04

Connection

1	BN
2	WH
3	BU
4	BK

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white