


Connecting cable with socket

ADOGF030MSS0005E03

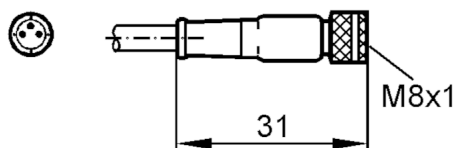

Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
-------------------	-----	-------------------

Operating conditions

Ambient temperature	[°C]	-25...100
---------------------	------	-----------

Protection	IP 68
------------	-------

Mechanical data

Weight	[g]	136.078
--------	-----	---------

Materials	TPE
-----------	-----

Moulded-body material	TPE
-----------------------	-----

Material nut	brass, nickel-plated
--------------	----------------------

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 5 m, PVC, yellow, Ø 4.3 mm; 3 x 0.25 mm² (128 x Ø 0.05 mm)

Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: TPE; Locking: brass, nickel-plated




W80510



Connecting cable with socket

ADOGF030MSS0005E03

Connection

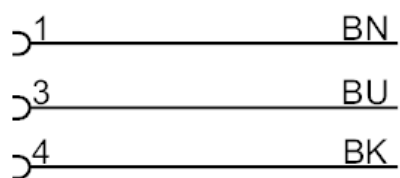

	Core colours :
BK =	black
BN =	brown
BU =	blue