


W80530



Connecting cable with socket

ADOAF030MSS0005E03

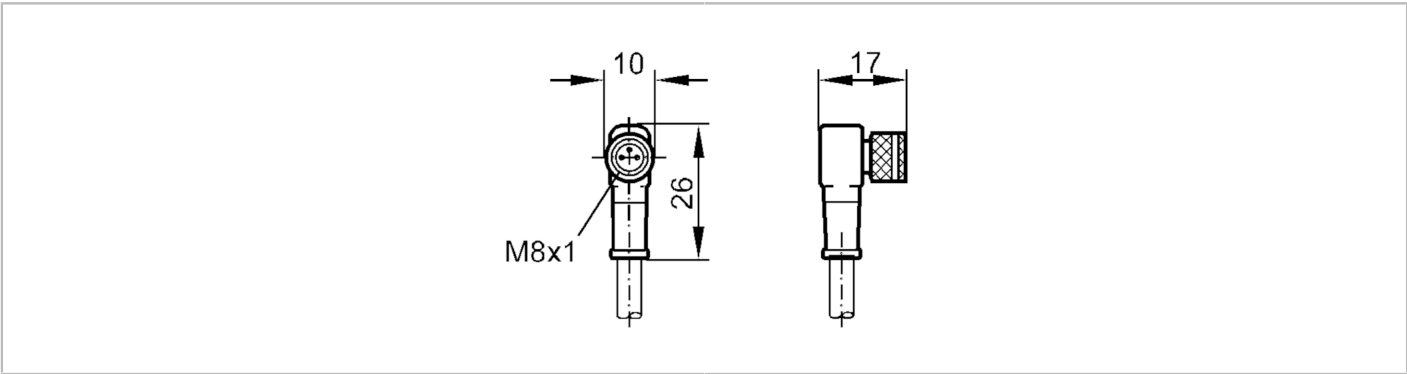

Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
-------------------	-----	-------------------

Operating conditions

Ambient temperature	[°C]	-25...100
---------------------	------	-----------

Protection		IP 68
------------	--	-------

Mechanical data

Weight	[g]	136.078
--------	-----	---------

Dimensions	[mm]	17 x 10 x 26
------------	------	--------------

Materials		TPE
-----------	--	-----

Moulded-body material		TPE
-----------------------	--	-----

Material nut		brass, nickel-plated
--------------	--	----------------------

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

Cable: 5 m, PVC, yellow, Ø 4.3 mm; 3 x 0.25 mm² (128 x Ø 0.05 mm)

Electrical connection - socket

Connector: 1 x M8, angled; coding: A; Moulded body: TPE; Locking: brass, nickel-plated



W80530



Connecting cable with socket

ADOAF030MSS0005E03

Connection



	Core colours :
BK =	black
BN =	brown
BU =	blue