


Connecting cable with socket

ADOGB030MKS0010X03

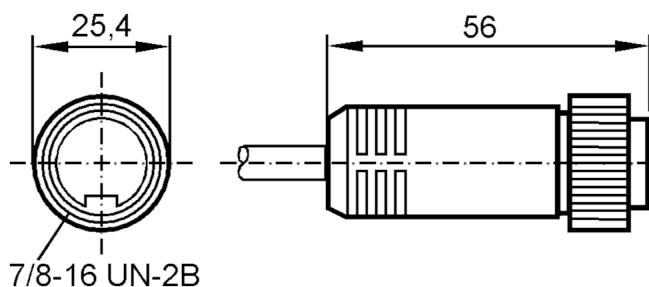

Application

Special feature

Gold-plated contacts

Electrical data

Operating voltage

[V]

< 600 AC/DC

Operating conditions

Ambient temperature

[°C]

-20...90

Protection

IP 68

Mechanical data

Weight

[g]

1415.207

Materials

PVC

Moulded-body material

PVC

Material nut

zinc, epoxy coated

Remarks

Pack quantity

 
1 pcs.

Electrical connection

Cable: 10 m, PVC, yellow, Ø 6 mm; 3 x 1.5 mm² / AWG 16

Electrical connection - socket

Connector: 1 x 7/8", straight; coding: A; Moulded body: PVC; Locking: zinc, epoxy coated; Contacts: gold-plated




W80603



Connecting cable with socket

ADOGB030MKS0010X03

Connection

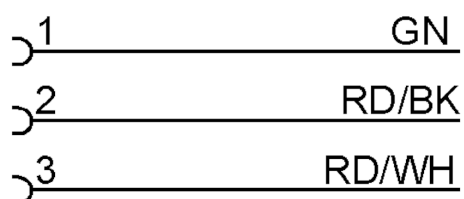

GN =
RD/BK =
RD/WH =

Core colours :
green
red/black
red/white