


W80654



Connecting cable with socket

ADOGB050MKS0002X05

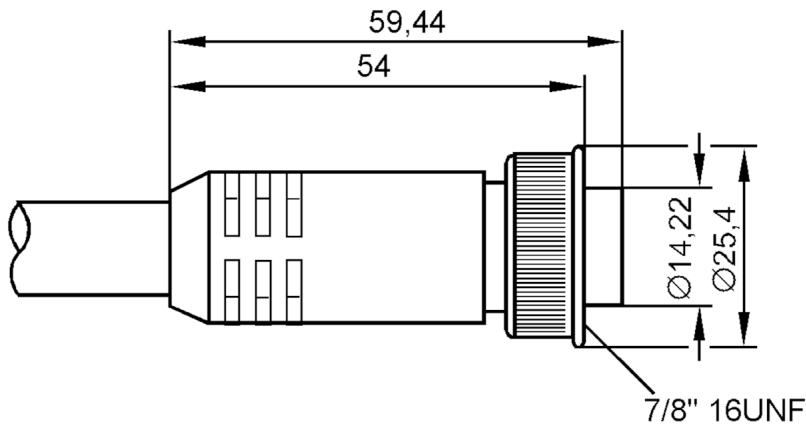

Electrical data		
Operating voltage	[V]	< 300 AC/DC
Operating conditions		
Ambient temperature	[°C]	-20...105
Protection		IP 68
Mechanical data		
Weight	[g]	172.365
Dimensions	[mm]	25.4 x 25.4 x 59.44
Materials		PVC
Moulded-body material		PVC
Material nut		zinc, epoxy coated
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 2 m, PVC, yellow, Ø 7.12 mm; 5 x 0.5 mm² / AWG 20		
Electrical connection - socket		
Connector: 1 x 7/8", straight; coding: A; Moulded body: PVC; Locking: zinc, epoxy coated		




W80654



Connecting cable with socket

ADOGB050MKS0002X05

Connection

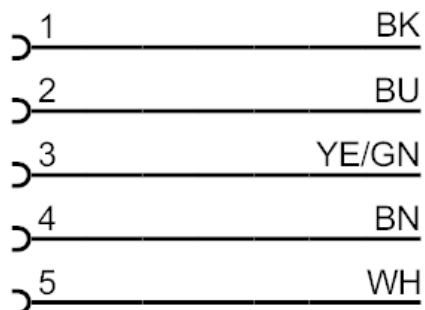

	Core colours :
BK =	black
BN =	brown
BU =	blue
GN/YE =	green/yellow
WH =	white