


Connecting cable with socket

ADOGB050MKS0004X05

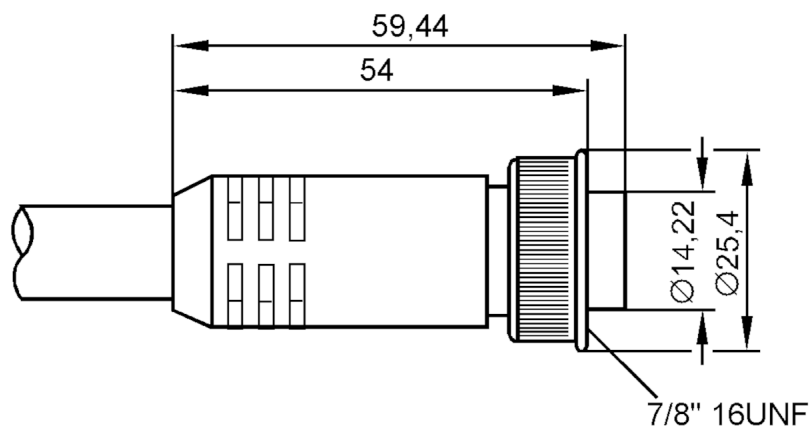

Electrical data

Operating voltage	[V]	< 300 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-20...105
Protection		IP 68

Mechanical data

Weight	[g]	381.017
Dimensions	[mm]	25.4 x 25.4 x 59.44
Materials		PVC
Moulded-body material		PVC
Material nut		zinc, epoxy coated

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 4 m, PVC, yellow, Ø 7.12 mm; 5 x 0.5 mm² / AWG 20

Electrical connection - socket

Connector: 1 x 7/8", straight; coding: A; Moulded body: PVC; Locking: zinc, epoxy coated

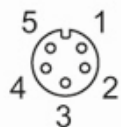


W80655



Connecting cable with socket

ADOGB050MKS0004X05

Connection

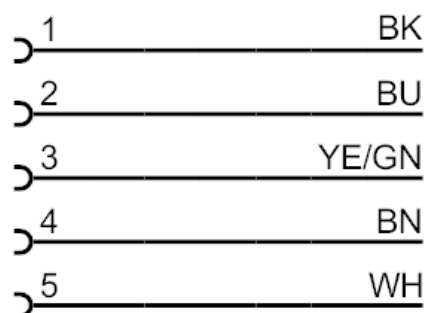

	Core colours :
BK =	black
BN =	brown
BU =	blue
GN/YE =	green/yellow
WH =	white