


Connecting cable with socket

ADOAB050MKS0004X05

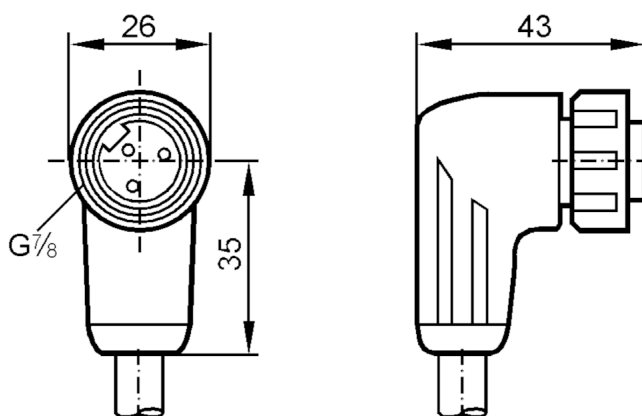

Electrical data

Operating voltage	[V]	< 250 AC
-------------------	-----	----------

Operating conditions

Ambient temperature	[°C]	-20...105
Protection		IP 68

Mechanical data

Weight	[g]	807.394
Dimensions	[mm]	43 x 26 x 35
Materials		PVC
Moulded-body material		PVC
Material nut		diecast zinc, epoxy coated

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 4 m, PVC, yellow, Ø 7.2 mm; 3 x 0.75 mm² (16 x Ø 0.5 mm)

Electrical connection - socket

Connector: 1 x 7/8", angled; coding: A; Moulded body: PVC; Locking: diecast zinc, epoxy coated

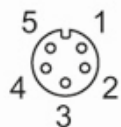


W80657



Connecting cable with socket

ADOAB050MKS0004X05

Connection

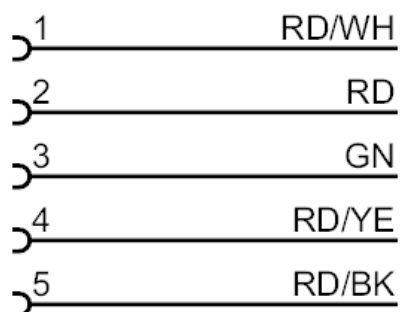

BK =	Core colours :	black
GN =		green
RD =		red
WH =		white
YE =		yellow