


W80300



Connecting cable with socket

ADOAH042MKS0002E03

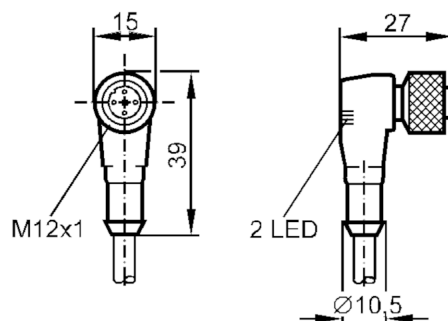

Electrical data

Operating voltage [V] 10...30 DC

Outputs

Electrical design PNP

Operating conditions

Ambient temperature [°C] -20...105

Protection IP 68

Mechanical data

Weight [g] 72.575

Dimensions [mm] 27 x 15 x 39

Materials PVC transparent

Moulded-body material PVC, transparent

Material nut zinc, epoxy coated

Displays / operating elements

Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity 1 pcs.



Connecting cable with socket

ADOAH042MKS0002E03

Electrical connection


Cable: 2 m, PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PVC, transparent; Locking: zinc, epoxy coated



Connection

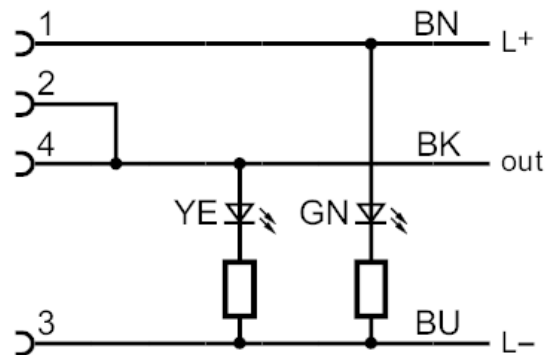

BN = Core colours : brown
BK = black
BU = blue