


W80310



Connecting cable with socket

ADOAH042MKS0005E03

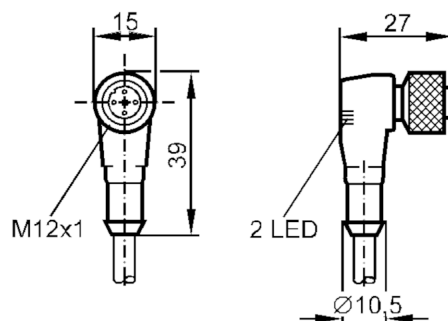

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-20...105
Protection		IP 68

Mechanical data

Weight	[g]	181.437
Dimensions	[mm]	27 x 15 x 39
Materials		PVC
Moulded-body material		PVC
Material nut		zinc, epoxy coated

Displays / operating elements

Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

W80310



Connecting cable with socket

ADOAH042MKS0005E03

Electrical connection


Cable: 5 m, PVC, yellow, Ø 5 mm; 3 x 0.34 mm²

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PVC; Locking: zinc, epoxy coated



Connection

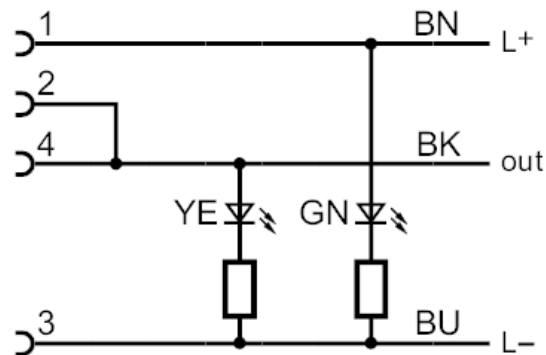

BN = Core colours : brown
BK = black
BU = blue