

Article de remplacement: EBC011

Technical drawing of the M23x1 connector showing side and front views with dimensions.

Side View (Top):

- Overall height: 28
- Height of the main body: 18

Front View (Bottom):

- Overall width: 152
- Width of the main body: 107
- Width of the flange: 4,5
- Overall height: 60
- Height of the flange: 39
- Thread specification: M23x1
- Thread specification: M12x1

Système	Sans silicone; contacts dorés
Sans silicone	oui

Tension d'alimentation	[V]	< 60 AC / < 75 DC
Classe de protection		II
Courant de sortie par module / emplacement	[A]	4
Courant de sortie total	[A]	10

Température ambiante	[°C]	-15...80
Protection		IP 67



Répartiteur


ZDO8H050MSS0000-00STAK190MSS

Données mécaniques		
Dimensions	[mm]	28 x 60 x 152
Matières		TPU
Matière du corps		TPU
Nombre d'emplacements répartiteur		8
Type connecteur		M12

Remarques	
Quantité	1 pièces

Raccordement électrique - Raccordement

Connecteur: 1 x M23; Corps: TPU; Contacts: dorées; Couple de serrage: 0,5 Nm

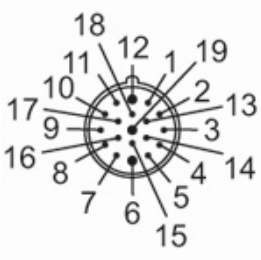

Raccordement

+	19	1 (1...8)
-	6	3 (1...8)
⊥	12	5 (1...8)
	15	4 (1)
	7	2 (1)
	5	4 (2)
	4	2 (2)
	16	4 (3)
	8	2 (3)
	3	4 (4)
	14	2 (4)
	17	4 (5)
	9	2 (5)
	2	4 (6)
	13	2 (6)
	11	4 (7)
	10	2 (7)
	1	4 (8)
	18	2 (8)

E11734



Répartiteur

ZDO8H050MSS0000-00STAK190MSS

Raccordement électrique - emplacement

Connecteur: 8 x M12; codage: A; Corps: TPU; Contacts: dorées; Couple de serrage: 0,5 Nm

