




EC2075

Steckersatz
für
CabinetController
CR0301/02
konfektionierbar

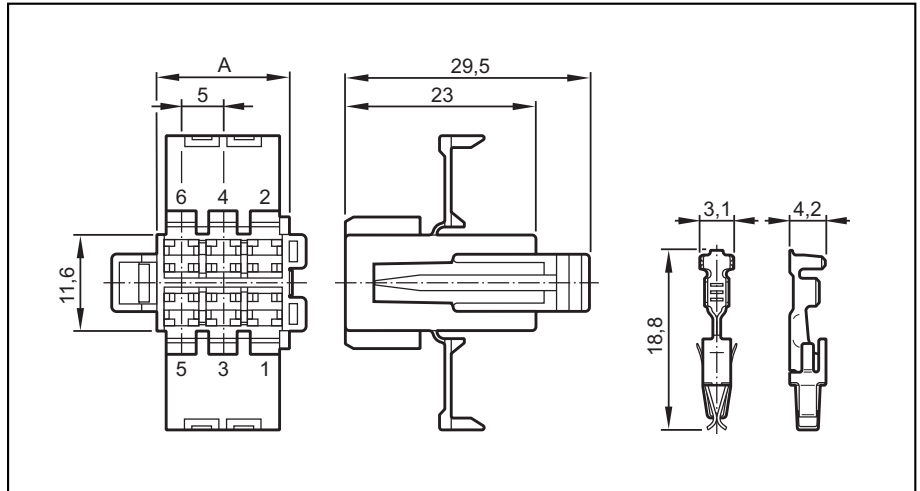

Technische Daten

**AMP Crimp-Buchsengehäuse
inkl. Crimp-Kontakte (Junior Power Timer)**

Lieferumfang

Gehäuse

Kontakte

Schutzart

Material (Gehäuse)


Material (Crimp-Kontakte)

1 x 6-polig, 2 x 10-polig, 3 x 18-polig
80

IP 20


PBT (schwarz)

 CuSn (verzinnt)




A = 11

 4-polig




A = 16

6-polig

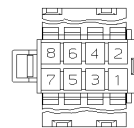

A = 21

8-polig

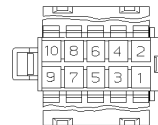


A = 26

10-polig




A = 36

14-polig

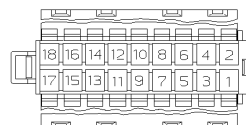

A = 46

18-polig

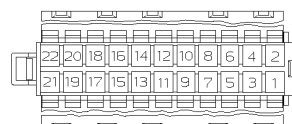

A = 56


22-polig



EC2075

Plug set
for
CabinetController
CR0301/02

wirable

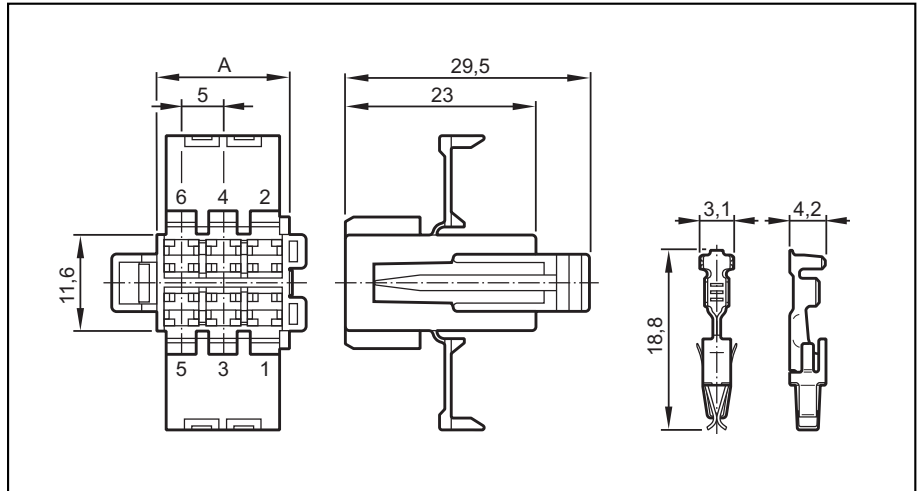

Technical data

Components
housing
contacts

Schutzart

Material (housing)

Material (contacts)


**AMP Crimp housing
incl. Crimp contacts (Junior Power Timer)**

1 x 6 pins, 2 x 10 pins, 3 x 18 pins
80

IP 20


PBT (black)

 CuSn (tin plated)




A = 11

 4 pins




A = 16

6 pins

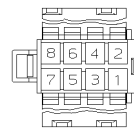


A = 21

8 pins

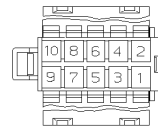


A = 26

10 pins

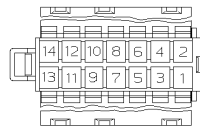


A = 36

14 pins

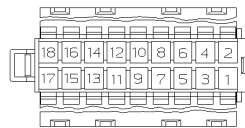

A = 46

18 pins

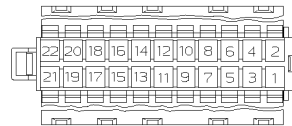

A = 56

22 pins