




phase-out article

Alternative articles: CR2042

When selecting an alternative article and accessories please note that technical data may differ!

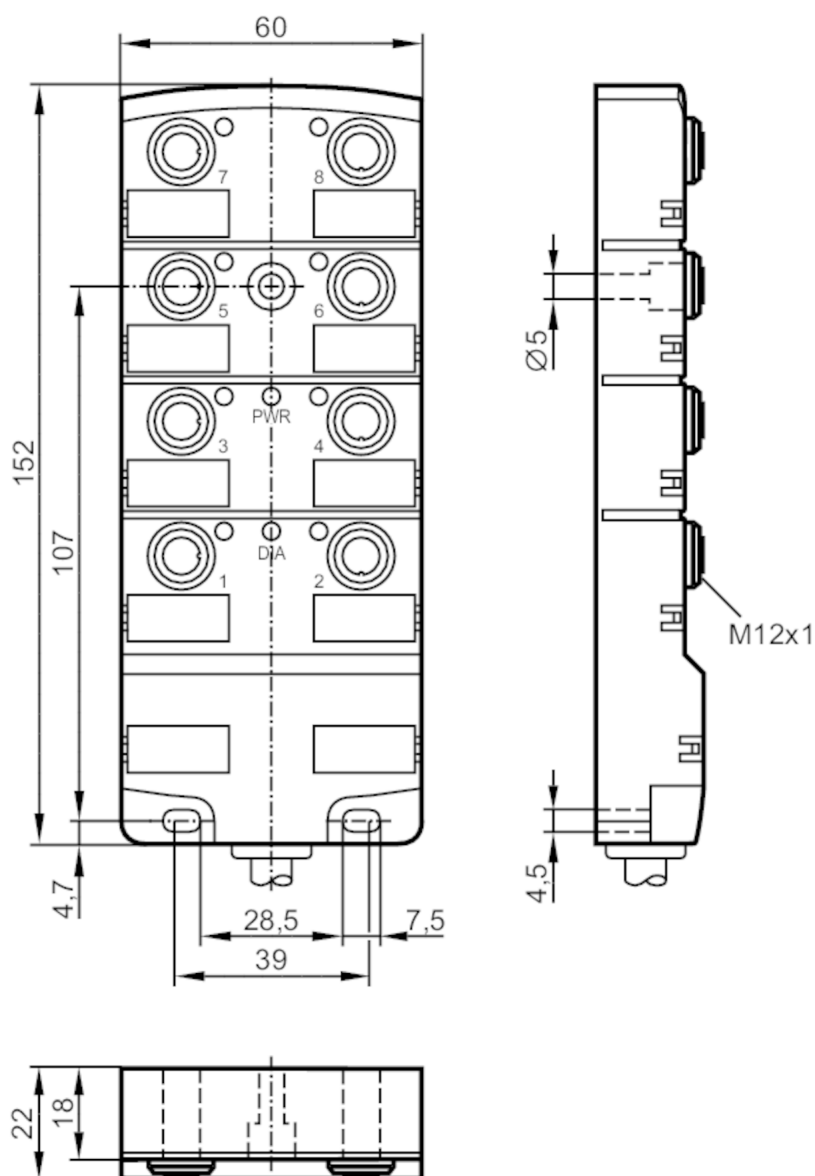

Electrical data

Operating voltage [V] 10...32 DC

Inputs / outputs

Total number of inputs and outputs	8
Number of inputs and outputs	Number of digital inputs: 4; Number of analogue inputs: 4; Number of digital outputs: 4

Inputs

Number of digital inputs	4
--------------------------	---

**I/O module for mobile machines**

R360/COMPACT-MODULE/I/8/O/4

Number of analogue inputs	4
Analogue input (voltage) [V]	0...10
Outputs	
Number of digital outputs	4
Number of PWM outputs	4
Software / programming	
Parameter setting options	input/output functions
Interfaces	
Number of CAN interfaces	1
Tests / approvals	
MTTF [years]	253
Mechanical data	
Weight [g]	479.8
Dimensions [mm]	152 x 60 x 22
Remarks	
Pack quantity	1 pcs.
Electrical connection	
Connector: 1 x M12	