

## Connecting cable with socket

ADOAH050VAS0025E05

Article no longer available - archive entry



## Application

|                    |                                          |
|--------------------|------------------------------------------|
| Special feature    | Free from silicone; Gold-plated contacts |
| Free from silicone | yes                                      |

## Electrical data

|                         |     |                   |
|-------------------------|-----|-------------------|
| Operating voltage       | [V] | < 30 AC / < 36 DC |
| Max. current load total | [A] | 4                 |

## Operating conditions

|                     |      |           |
|---------------------|------|-----------|
| Ambient temperature | [°C] | -25...100 |
| Protection          |      | IP 68     |

## Mechanical data

|                       |      |                                 |
|-----------------------|------|---------------------------------|
| Dimensions            | [mm] | 26.5 x 15 x 38.5                |
| Materials             |      | PVC                             |
| Moulded-body material |      | PVC                             |
| Material nut          |      | stainless steel (1.4404 / 316L) |

## Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

# E10953



## Connecting cable with socket


ADOAH050VAS0025E05

### Electrical connection

Cable: 25 m, PVC, orange, Ø 5.6 mm; 5 x 0.25 mm<sup>2</sup>

### Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm

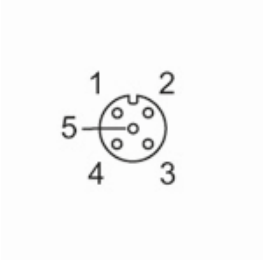

### Connection

|   |    |
|---|----|
| 1 | BN |
| 2 | WH |
| 3 | BU |
| 4 | BK |
| 5 | GY |

|      |                |
|------|----------------|
|      | Core colours : |
| BK = | black          |
| BN = | brown          |
| BU = | blue           |
| GY = | grey           |
| WH = | white          |