



Connecting cable with socket

ADOGF040VAS0025E04

Article no longer available - archive entry

Alternative articles: EVT137

When selecting an alternative article and accessories please note that technical data may differ!

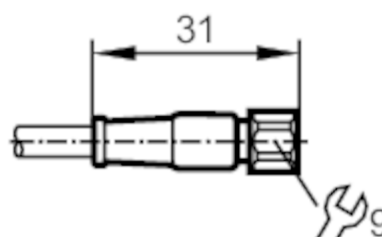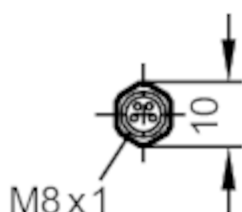

Application

Special feature	Free from silicone
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III
Max. current load total	[A]	3

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

Mechanical data

Weight	[g]	896.4
Dimensions	[mm]	10 x 10 x 31
Materials		PVC
Moulded-body material		PVC
Material nut		stainless steel (1.4404 / 316L)

Remarks

Pack quantity	1 pcs.
---------------	--------

E11225



Connecting cable with socket


ADOGF040VAS0025E04

Electrical connection


Cable: 25 m, PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Tightening torque: 0.6...0.7 Nm
Connector: 1 x M8, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Tightening torque: 0.6...0.7 Nm

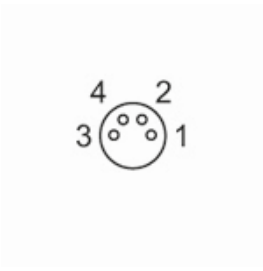

Connection

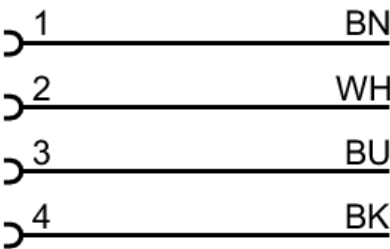

Core colours :
BK = black
BN = brown
BU = blue
WH = white