


Fibre optic diffuse reflection sensor

FT-00-M-V-R4/2,5m

Article no longer available - archive entry

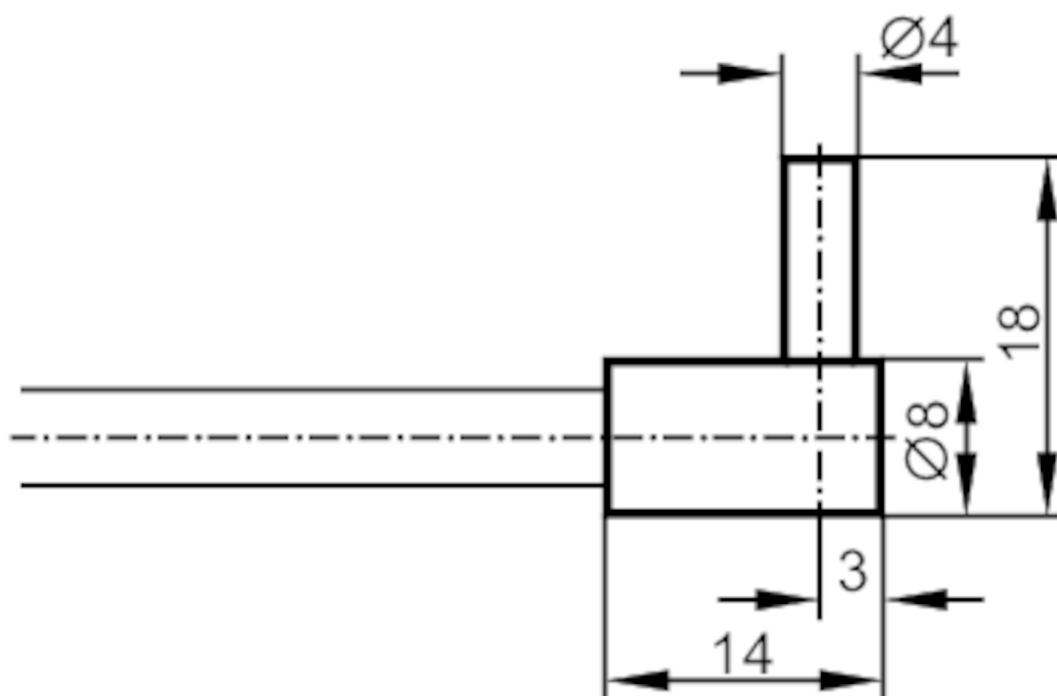

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic amplifier type

OKF; OUF

OKF

Range fibre optics

[mm]

28

OUF

Range fibre optics

[mm]

28

Operating conditions

Ambient temperature

[°C]

-20...150

Mechanical data

Version of sensing head

angled

Sensing head diameter

[mm]

4

Sensing head length

[mm]

10

Total length

[mm]

2500

Min. bending radius

[mm]

20

Fibre material

glass

Fibre head material

stainless steel (1.4305 / 303)

E20531



Fibre optic diffuse reflection sensor

FT-00-M-V-R4/2,5m

Fibre sheath material	metal silicone
Remarks	
Pack quantity	1 pcs.