



Process adapter for SMS pipe fitting


ADAPT IFM-SMS DN50 (2)

phase-out article

Alternative articles: E33732

When selecting an alternative article and accessories please note that technical data may differ!

The alternative article requires the use of a new sensor with Aseptoflex Vario external thread

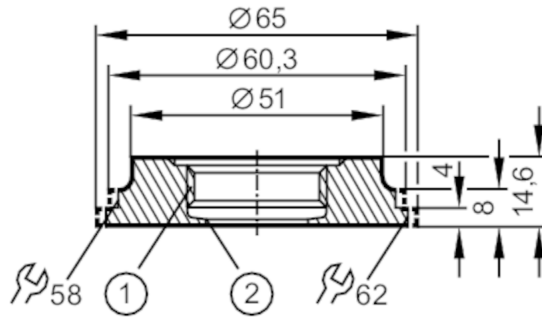

- 1 Aseptoflex thread
- 2 Aseptoflex sealing edge

EC 1935/2004 

Application	
Pressure rating	[bar] 25
Tests / approvals	
Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
Safety instructions	The compatibility between medium and product material has to be checked in all applications.
Mechanical data	
Weight	[g] 273.8
Materials	stainless steel (316L/1.4404)
Sensor connection	Aseptoflex
Process connection	SMS pipe fitting DN50 (2")
Surface characteristics Ra/Rz of the wetted parts	0.4 / 4
Hygienic equipment class to DIN 11866	H4
Remarks	
Pack quantity	1 pcs.