




Coaxial pipe for level sensors

LR COAX TUBE G3/4 L1000

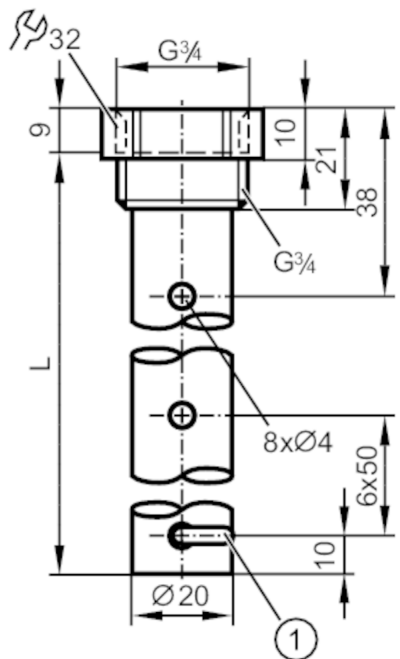

1 fixing bracket for centring piece

CRN

| Application | | |
|--|--------|---|
| Design | | for level sensors LR |
| Medium temperature | [°C] | -40...200 |
| Pressure rating | [bar] | 16 |
| Vacuum resistance | [mbar] | -1000 |
| MAWP (for applications according to CRN) | [bar] | 16 |
| Mechanical data | | |
| Weight | [g] | 570 |
| Materials | | Coaxial pipe: stainless steel (304/1.4301); Sealing: NBR reinforced fibre; Centring piece: PPS reinforced fibre; fixing bracket: stainless steel (301/1.4310) |
| Sensor connection | | threaded connection G 3/4 internal thread |
| Process connection | | threaded connection G 3/4 external thread |
| Length L | [mm] | 1000 |
| Accessories | | |
| Items supplied | | Sealing: 1 |
| Accessories (optional) | | Centring piece for coaxial pipes: 1, E43222 |
| Remarks | | |
| Remarks | | When used under DNV GL conditions mounting of an additional centring piece is required |
| Pack quantity | | 1 pcs. |