


EC2116



Combined antenna for navigation and radio

R360/CANremote/ANTENNA/DUAL

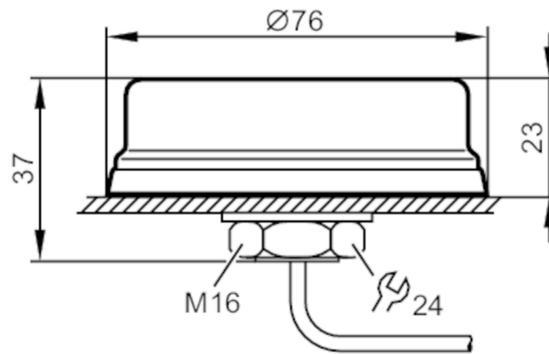

Electrical data

Operating voltage [V]	via the internal wire of the GPS connection
Current consumption [mA]	< 30

Operating conditions

Ambient temperature [°C]	-40...85
Protection	IP 66; (when mounted (outer washer and O-ring in the thread area))

Mechanical data

Weight [g]	156.9
Type of mounting	Gewinde
Tightening torque [Nm]	< 5

Remarks

Remarks	<p>When mounting the antenna(s) in vehicles avoid the vicinity of fuel tanks, vessels with explosives or insufficiently screened electronic components.</p> <p>Do not install antenna inside closed metal construction (e.g. in driver's cabin).</p> <p>Clean the mounting surface before the installation.</p> <p>Do not extend or shorten antenna cable.</p> <p>Avoid direct exposure to steam or high-pressure cleaning during car wash.</p> <p>Radio communication can affect the function of electronic devices that are not correctly shielded.</p> <p>Contact the manufacturer of the corresponding device in case of any interference.</p>
Pack quantity	1 pcs.

Electrical connection

Cable: 3 m

Electrical connection - GPS

Connector: SMA

Electrical connection - GSM

Connector: FME