




EC2017

Stecker
für
Dialoggeräte
TDM R360
konfektionierbar

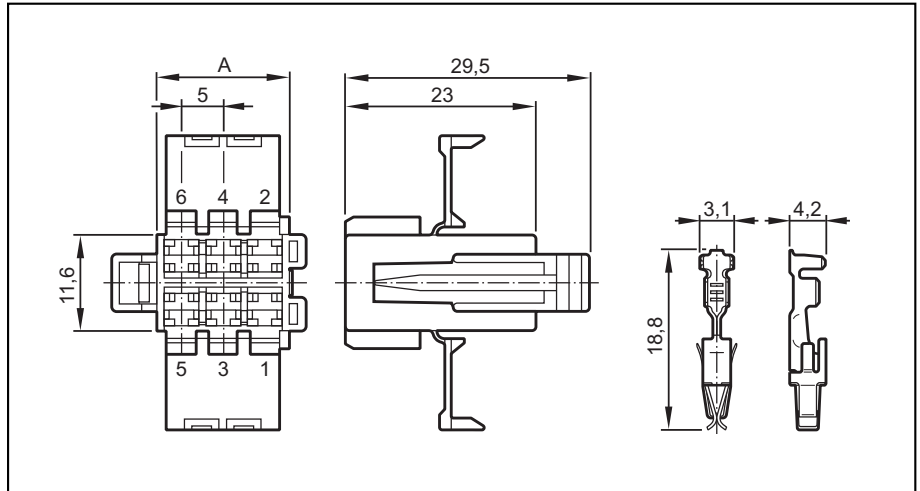

Technische Daten

Lieferumfang
Schutzart
Material (Gehäuse)
Material (Crimp-Kontakte)








**AMP Crimp-Buchsengehäuse
inkl. Crimp-Kontakte (Junior Power Timer)**

1 x 6-polig

IP 20

  PBT (schwarz)

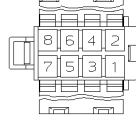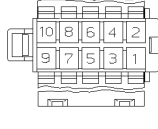
CuSn (verzinnt)

	A = 11	<input type="checkbox"/> 4-polig
	A = 16	<input checked="" type="checkbox"/> 6-polig
	A = 21	<input type="checkbox"/> 8-polig
	A = 26	<input type="checkbox"/> 10-polig
	A = 36	<input type="checkbox"/> 14-polig
	A = 46	<input type="checkbox"/> 18-polig
	A = 56	<input type="checkbox"/> 22-polig



EC2017

Plug
for
dialogue modules
TDM R360
wirable

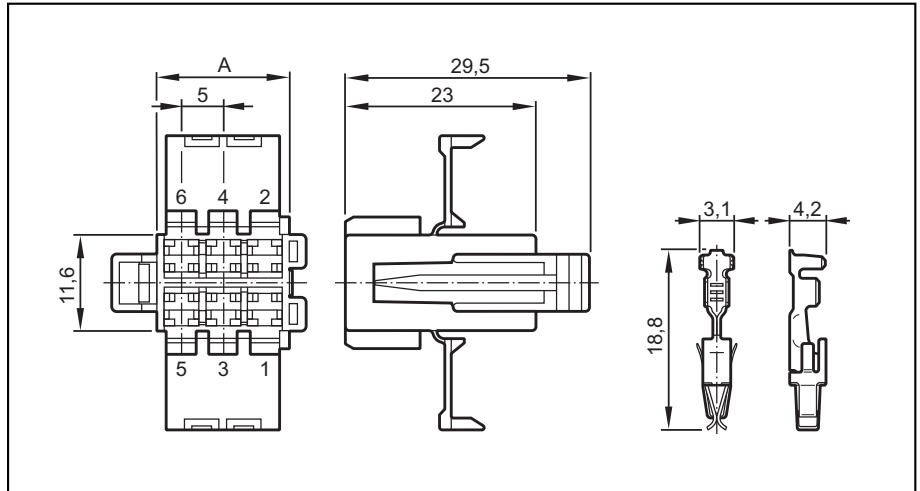

Technical data

**AMP Crimp housing
incl. Crimp contacts (Junior Power Timer)**

Components

1 x 6 pins

Protection


IP 20

Material (housing)

PBT (black)


Material (contacts)

 CuSn (tin plated)




A = 11

 4 pins




A = 16

6 pins

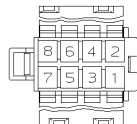

A = 21

8 pins

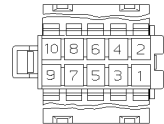


A = 26

10 pins



A = 36

14 pins

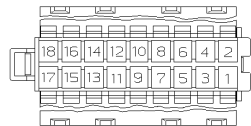

A = 46

18 pins



A = 56

22 pins