

# E33021



## Process adapter Varivent


ADAP IFM-VARIV D=50(DN25/1)

Article no longer available - archive entry

Alternative articles: E33721

When selecting an alternative article and accessories please note that technical data may differ!

The alternative article requires the use of a new sensor with Aseptoflex Vario external thread

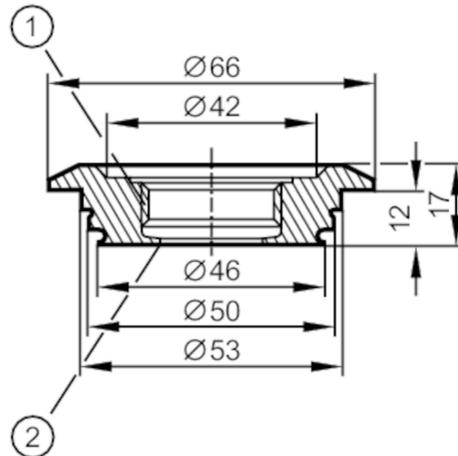

- 1 Aseptoflex thread
- 2 Aseptoflex sealing edge

EC 1935/2004 EHEDG Certified 

| Application                                       |                                     |
|---|-------------------------------------|
| Pressure rating                                   | [bar] 25                            |
| Mechanical data                                   |                                     |
| Weight  | [g] 241.8                           |
| Materials   | stainless steel (1.4404 / 316L)     |
| Sensor connection                                 | Aseptoflex                          |
| Process connection                                | Varivent Form F, DN25 (1"), Ø 50 mm |
| Surface characteristics Ra/Rz of the wetted parts | 0.4 / 4                             |
| Hygienic equipment class to DIN 11866             | H4                                  |
| Remarks   |                                     |
| Pack quantity                                     | 1 pcs.                              |