


DX2033



Multifunction display for monitoring revolution, speed and time

DISPLAY/FX460/PNP OUT/DC

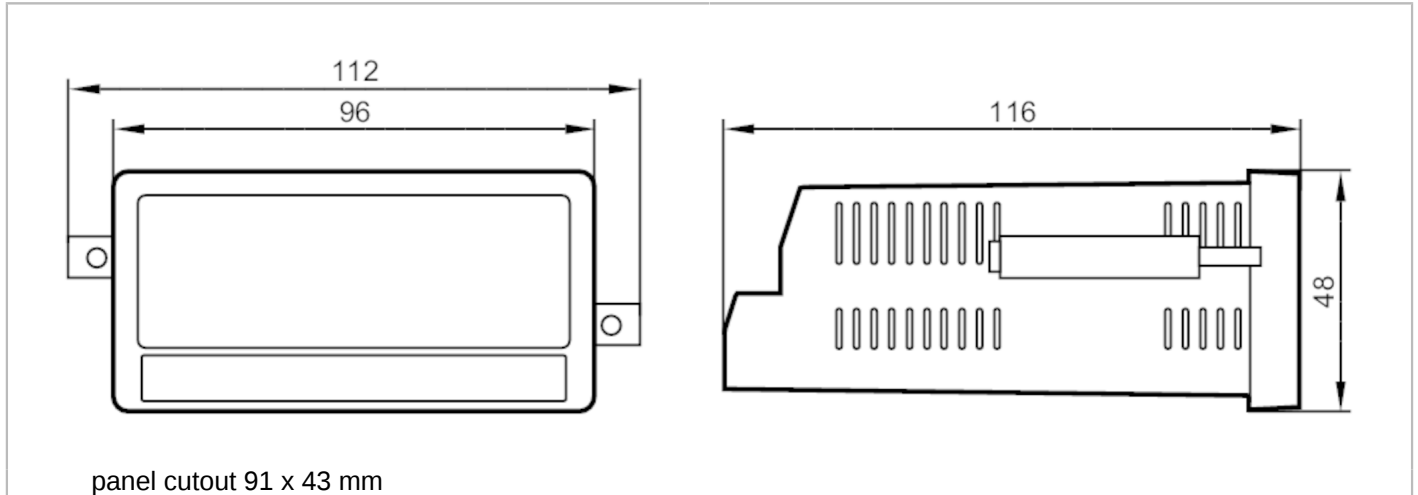

Product characteristics	
Dimensions	[mm] 48 x 112 x 116
Application	
Application	universal evaluation and display for all physical units which can be derived from pulse sequences
Electrical data	
Operating voltage	[V] 18...30 DC
Current consumption	[mA] 100
Inputs / outputs	
Number of inputs and outputs	Number of digital inputs: 2; Number of digital outputs: 4
Inputs	
Number of digital inputs	2
Outputs	
Number of digital outputs	4
Overload protection	yes
Operating conditions	
Ambient temperature	[°C] -20...60
Storage temperature	[°C] -25...70
Protection	IP 65
Protection rating terminals	IP 20
Tests / approvals	
EMC	EN 61000-6-2
	EN 61000-6-3
	EN 61000-6-4
Mechanical data	
Weight	[g] 299
Type of mounting	panel cutout: 91 x 43 mm
Dimensions	[mm] 48 x 112 x 116
Materials	Noryl UL94-V-0

DX2033



Multifunction display for monitoring revolution, speed and time

DISPLAY/FX460/PNP OUT/DC


Displays / operating elements

Display	colour display	full graphic LCD display, touch screen
---------	----------------	--

Electrical connection

screw terminals:

Connection

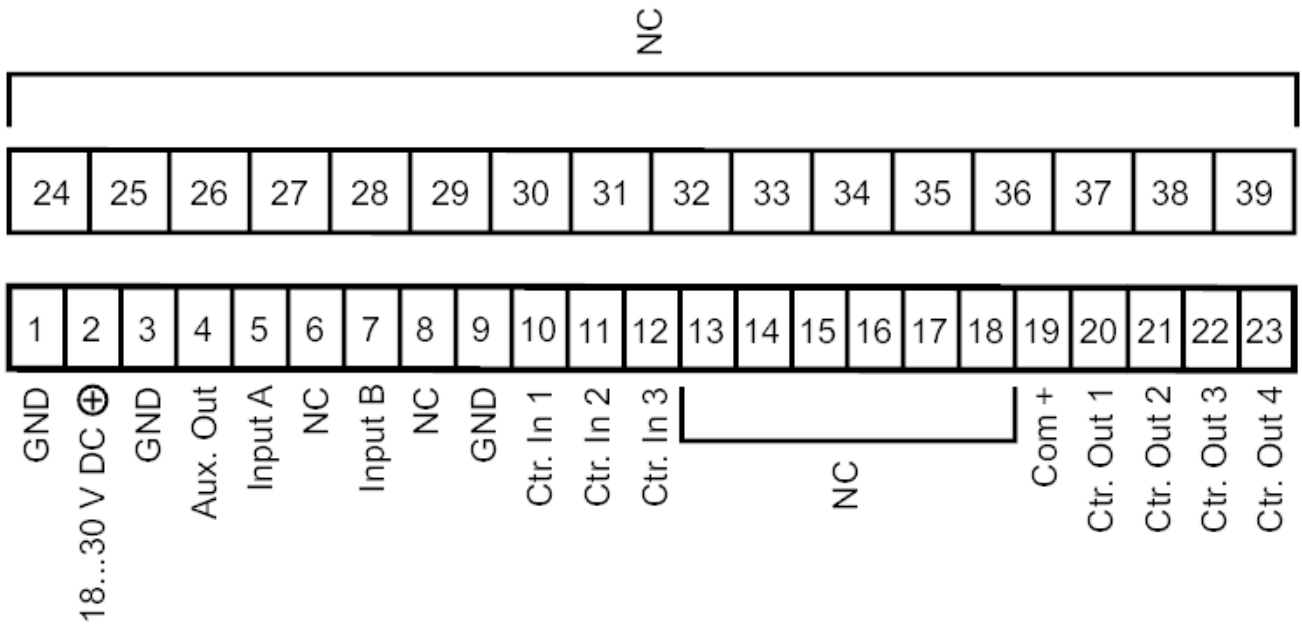

NC: not used