


# E10535



## Connecting cable with socket

ADOGH040MSS07,5E04

Article no longer available - archive entry

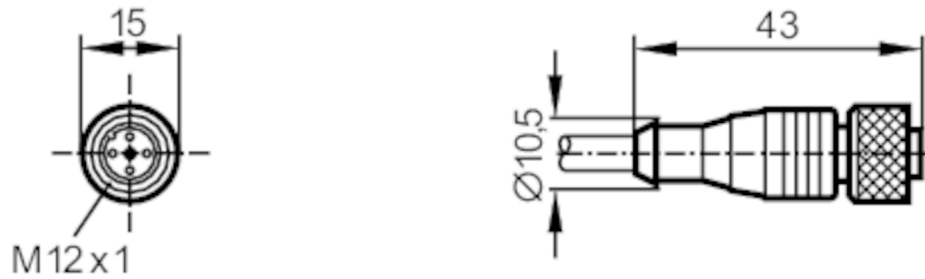

### Electrical data

Operating voltage [V] < 250 AC / < 300 DC

### Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

### Mechanical data

Dimensions [mm] 15 x 15 x 43

Materials TPU

Material nut brass, nickel-plated

### Remarks

 
Pack quantity 1 pcs.

### Electrical connection

Cable: 7.5 m, PVC, orange, Ø 5 mm; 4 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Electrical connection - socket

Connector: 1 x M12, straight; Moulded body: TPU; Locking: brass, nickel-plated




# E10535



## Connecting cable with socket

ADOGH040MSS07,5E04

### Connection

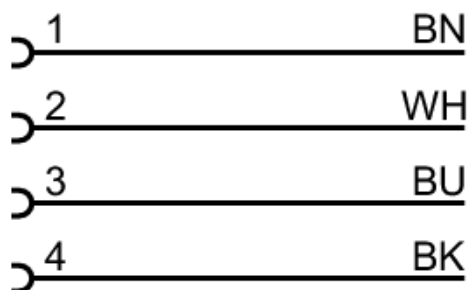

Core colours :

BN =	brown
BK =	black
BU =	blue
WH =	white

Article no longer available - archive entry