


# E11442



## Connection cable

VDOGF040MSS00,6H04STGH040MSS

Article no longer available - archive entry

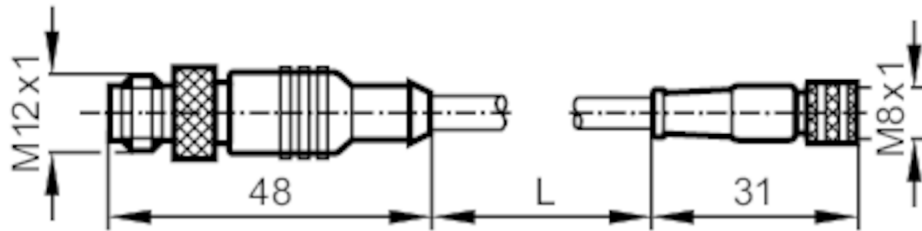


Application	
Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 60 AC / < 75 DC
Protection class	III
Max. current load total [A]	3
Operating conditions	
Ambient temperature [°C]	-25...85
Protection	IP 68
Mechanical data	
Materials	PUR
Material nut	brass, nickel-plated / brass, nickel-plated
Remarks	
Pack quantity	1 pcs.
Electrical connection - plug	
Connector: 1 x M12, straight; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm	

# E11442


 
## Connection cable


VDOGF040MSS00,6H04STGH040MSS



### Electrical connection

Cable: 0.6 m, PUR, Halogen-free, black,  $\varnothing$  4.4 mm; 4 x 0.25 mm<sup>2</sup> (32 x  $\varnothing$  0.1 mm )

### Connection

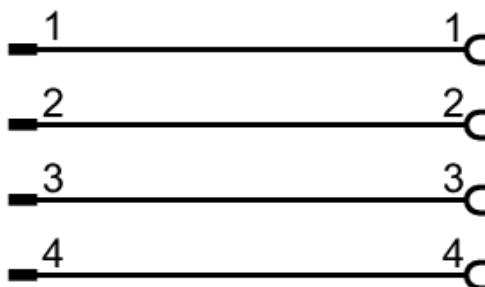

### Electrical connection - socket

Connector: 1 x M8, straight; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm



Article no longer available - archive entry