


# E11579



## Connection cable

VDOAH043MSS0007H04STGH040MSS

Article no longer available - archive entry

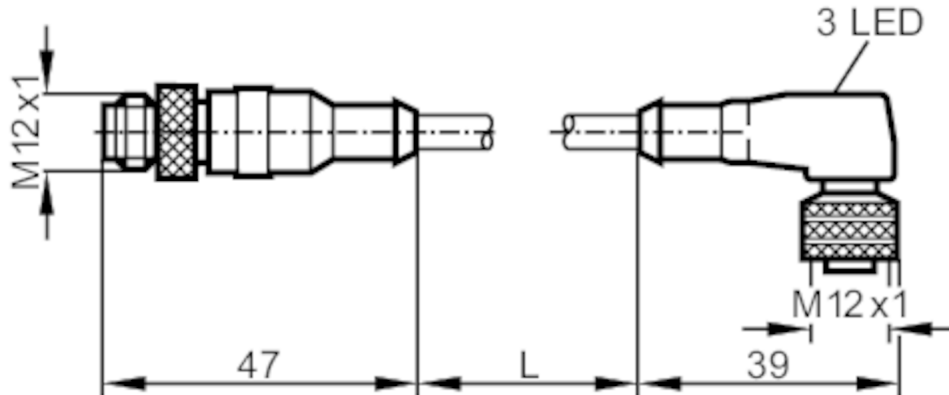

### Application

Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes

### Electrical data

Operating voltage	[V]	10...30 DC
Max. current load total	[A]	3

### Outputs

Electrical design	PNP
-------------------	-----

### Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 68

### Mechanical data

Materials	PUR
Material nut	brass, nickel-plated / brass, nickel-plated

### Displays / operating elements

Display	switching status	2 x LED, yellow
	operation	1 x LED, green

### Remarks

Pack quantity	1 pcs.
---------------	--------

### Electrical connection - plug

Connector: 1 x M12, straight; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm

# E11579



## Connection cable


VDOAH043MSS0007H04STGH040MSS



### Electrical connection


Cable: 7 m, PUR, Halogen-free, black, Ø 5 mm; 4 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Connection

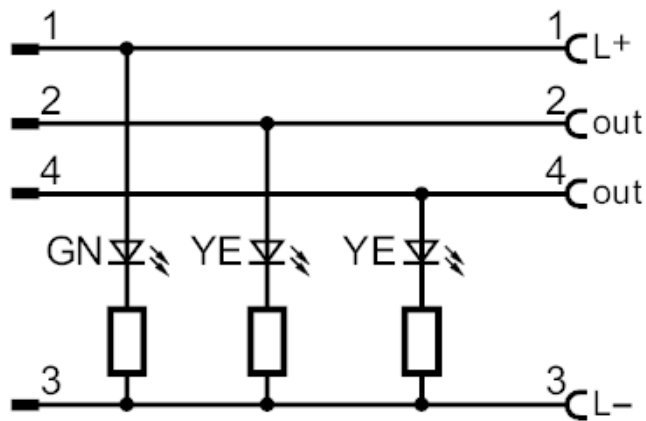

### Electrical connection - socket

 Connector: 1 x M12, angled; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm



Article no longer available - archive entry