

E20143




Fibre optic diffuse reflection sensor

FT-00-A-A-M6/0,15M

Article no longer available - archive entry

Alternative article: E20055 When selecting an alternative article and accessories please note that technical data may differ! – When selecting an alternative article and accessories please note that technical data may differ!

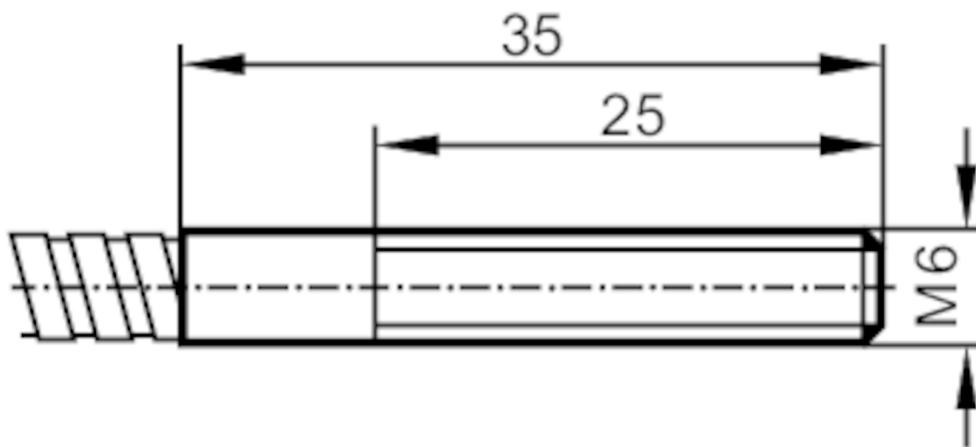

Application	
Function principle	Diffuse reflection sensor
Detection zone	
Range with fibre optic amplifier type	OKF; OUF
OKF	
Range fibre optics [mm]	40
OUF	
Range fibre optics [mm]	40
Operating conditions	
Ambient temperature [°C]	-40...290

E20143



Fibre optic diffuse reflection sensor

FT-00-A-A-M6/0,15M

Mechanical data	
Version of sensing head	straight
Sensing head thread	M6
Sensing head length [mm]	35
Total length [mm]	150
Min. bending radius [mm]	20
Materials	Adapter: ABS
Fibre material	glass
Fibre head material	aluminium
Fibre sheath material	aluminium
Remarks	
Pack quantity	1 pcs.

Article no longer available - archive entry

Alternative article: E20055 When selecting an alternative article and accessories please note that technical data may differ! – When selecting an alternative article and accessories please note that technical data may differ!