


E20430



带插座连接电缆
ADOGB030MSS0002E03

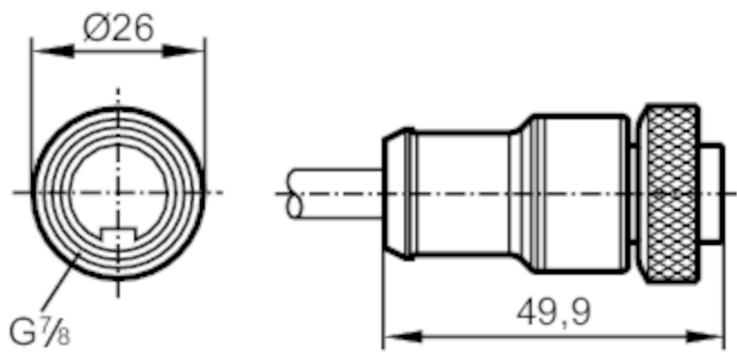

电气数据		
工作电压	[V]	10...30 DC
工作条件		
环境温度	[°C]	-40...80
外壳防护等级		IP 68
机械技术数据		
重量	[g]	117.5
尺寸	[mm]	26 x 26 x 49.9
原材料		TPU
模制主体材料		TPU
滚花螺母的材料		TPU
注释		
包装单位		1 件

E20430



带插座连接电缆


ADOGB030MSS0002E03

电气连接


电缆: 2 m, PVC, 黑色, Ø 5.4 mm; 3 x 0.5 mm² (16 x Ø 0.2 mm)

电气连接 - 插座

接插件: 1 x 7/8", 直型; 译码: A; 成型体: TPU; 锁定: TPU

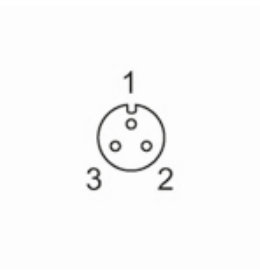

接口

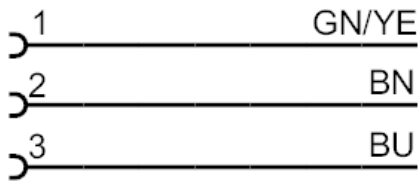

BN = 芯线颜色 : 棕色
BU = 蓝色
GN/YE = 绿色/黄色