




## 移动控制器的可接线插头

BasicContact-Set/for CR0421

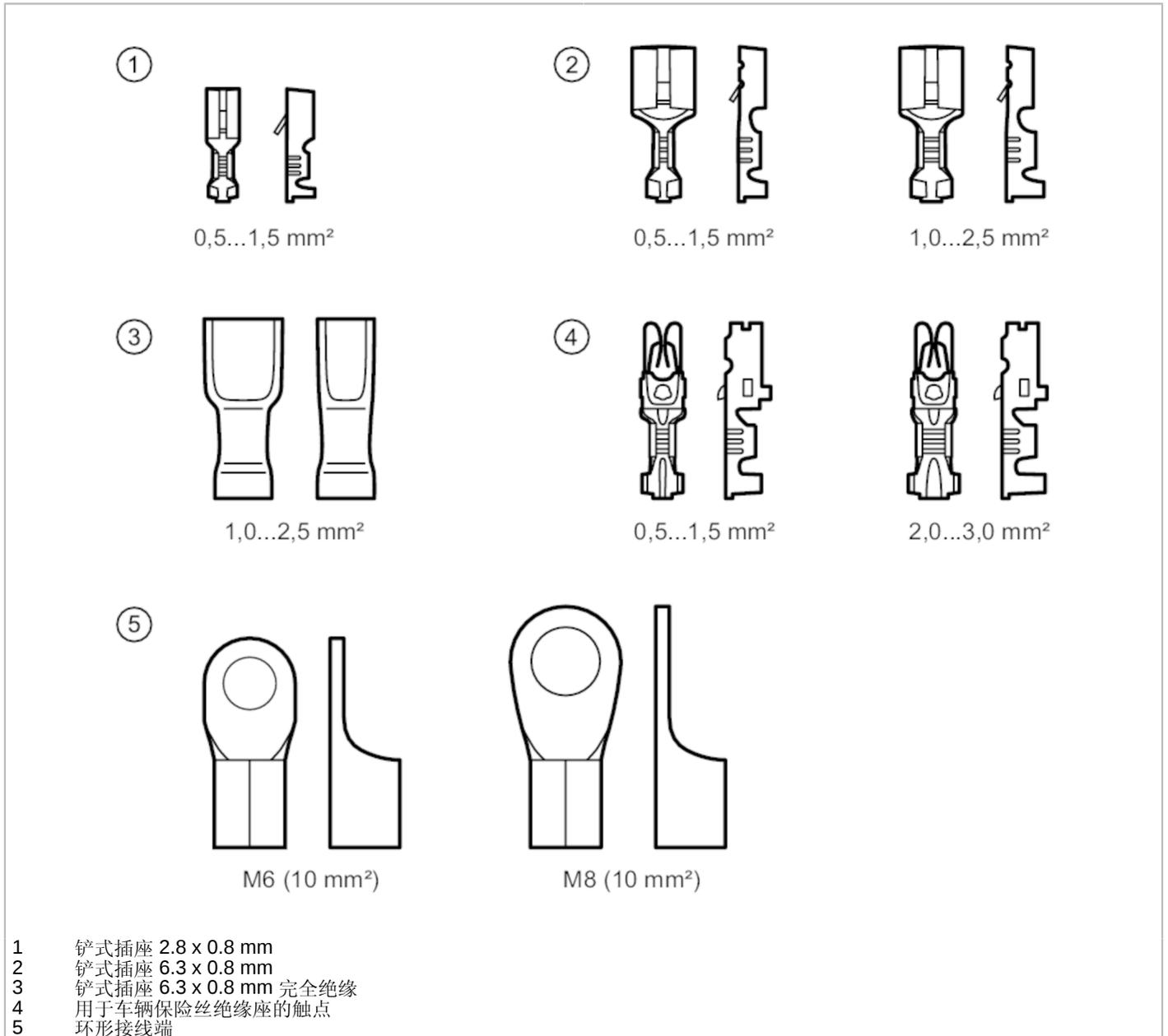

<b>应用</b>	
设计	用于BasicRelay, 连接BasicRelays, CR0421
<b>机械技术数据</b>	
重量	[g] 85.5
尺寸	[mm] 134.5 x 50.6 x 210

# EC0457



## 移动控制器的可接线插头

BasicContact-Set/for CR0421

### 附件

#### 供货范围

用于继电器触点的刀片母接线端子: 10 x 2,8 x 0,8 mm (0,5...1,0 mm <sup>2</sup> ), DIN 46340
用于继电器触点的刀片母接线端子: 20 x 6,3 x 0,8 mm (0,5...1,0 mm <sup>2</sup> ), DIN 46340
用于继电器触点的刀片母接线端子: 20 x 6,3 x 0,8 mm (1,0...2,5 mm <sup>2</sup> ), DIN 46340
用于电源分配器刀片母接线端子: 20 x 6,3 x 0,8 mm (1,0...2,5 mm <sup>2</sup> ), 完全绝缘 DIN 46245
用于车辆保险丝绝缘座的触点: 6 x 0,5...1,5 mm <sup>2</sup>
用于车辆保险丝绝缘座的触点: 4 x 2,0...3,0 mm <sup>2</sup>
用于电源的环形接线端: 1 x M6 (10 mm <sup>2</sup> ), DIN 46234
用于电源的环形接线端: 1 x M8 (10 mm <sup>2</sup> ), DIN 46234
螺母: 1 x M6, 镀锌的 ISO 4032
螺母: 1 x M8, 镀锌的 ISO 4032

### 电气连接

#### 接线端子: