


E3M120



Connection cable

MCI CONNECTION CABLE 0.25M

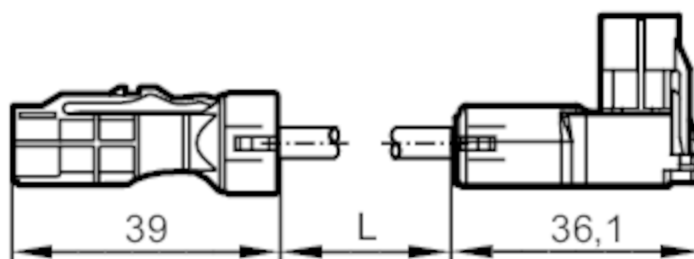

Operating conditions

Ambient temperature	[°C]	-40...105
Protection		IP 67

Mechanical data

Weight	[g]	38.1
Drag chain suitability		yes
Drag chain suitability	bending radius for fixed installation	≥ 40 mm

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 0.25 m, TPU, black