


E3M131



Connecting cable with socket

POWER SUPPLY CABLE O3M ILLUMINATION 2M

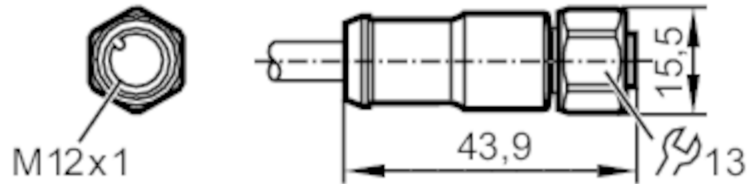

Operating conditions

| | | |
|---------------------|------|----------|
| Ambient temperature | [°C] | -40...85 |
| Protection | | IP 68 |

Mechanical data

| | | |
|------------------------|---------------------------------------|--------------------|
| Weight | [g] | 133.8 |
| Dimensions | [mm] | 15.5 x 15.5 x 43.9 |
| Materials | | PUR |
| Material nut | | diecast zinc |
| Drag chain suitability | | yes |
| Drag chain suitability | bending radius for fixed installation | ≥ 30 mm |

Remarks


| | |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

Electrical connection

Cable: 2 m, PUR, black, Ø 6 mm; 4 x 0.75 mm²

Electrical connection - socket

Connector: 1 x M12, straight; Moulded body: PUR; Locking: diecast zinc; Contacts: gold-plated

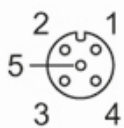

E3M131



Connecting cable with socket

POWER SUPPLY CABLE O3M ILLUMINATION 2M

Connection

