


E11898



Connection cable

VSTGN040ZDS0002E04STGP080--S

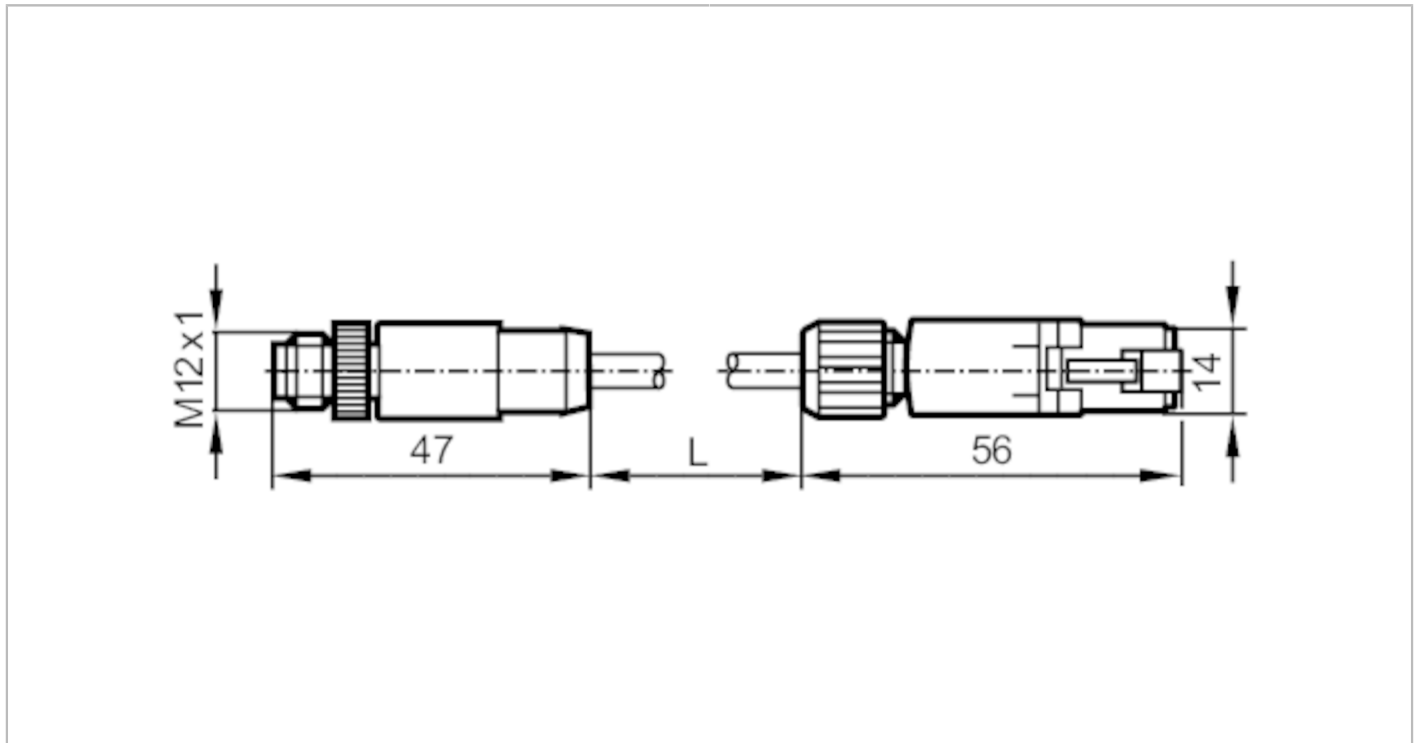

Application	
Design	Ethernet cable
Application	cross-over patch cable; patch cable
Operating conditions	
Ambient temperature [°C]	-25...70
Protection	IP 67; IP 42; (M12 plug / RJ45 plug)
Mechanical data	
Weight [g]	163.5
Materials	PUR / PC
Material nut	diecast zinc, nickel-plated
Remarks	
Pack quantity	1 pcs.

Electrical connection - plug M12

Connector: 1 x M12, straight; Moulded body: PUR; Locking: diecast zinc, nickel-plated; Tightening torque: 0.7...0.9 Nm



E11898




Connection cable

VSTGN040ZDS0002E04STGP080--S

Electrical connection

Cable: 2 m, PVC, green, \varnothing 6.2 mm; 4 x 0.38 mm²

Connection

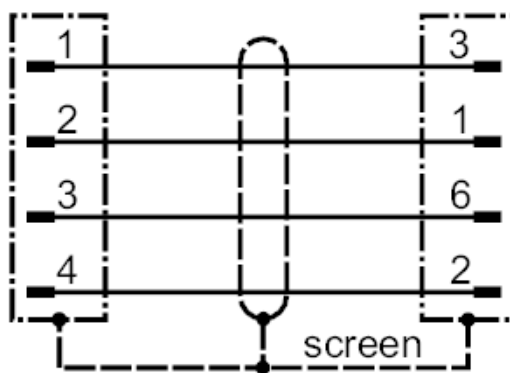

Electrical connection - plug RJ45

Connector: 1 x RJ45, straight; Moulded body: PC

