


Process adapter DIN 11864

ADAPT DIN11864-3-NKS-A/DN32/G1 3A

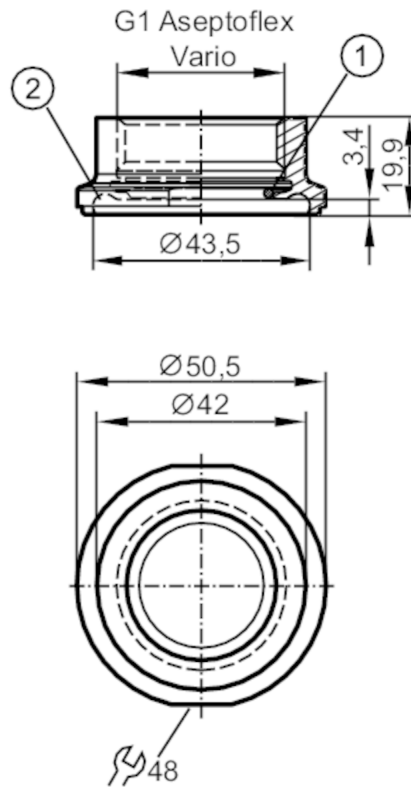

- 1 O-ring (included)
2 groove for O-ring to DIN 11864-3-R-34x5

EHEDG Tested

Application

Design	for pipes, for units with Aseptoflex Vario adapter, for pipes, DN 32 (DIN 11866, Reihe A), DN 32 (DIN 11866, Reihe A)
Pressure rating [bar]	40

Tests / approvals

Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
Safety instructions	The compatibility between medium and product material has to be checked in all applications.

Mechanical data

Weight [g]	130.5
Materials (wetted parts)	stainless steel (1.4435 / 316L) ; surface characteristics : Ra<0,4 / Rz 4
Sensor connection	G 1 internal thread Aseptoflex Vario
Process connection	Clamp DN32 DIN 11864-3-A-NKS
Sealing	Gasket
Hygienic equipment class to DIN 11866	H4

Accessories

Items supplied	O-ring: 1 x 24 x 2, EPDM, FDA compliant, E30054
----------------	---

E33243



Process adapter DIN 11864

ADAPT DIN11864-3-NKS-A/DN32/G1 3A

Accessories (optional)	O-ring: 1 x 24 x 2, FKM, FDA compliant, E30123
	sealing ring: 1, PEEK, FDA compliant, E30124
Remarks	
Pack quantity	1 pcs.