




## Process adapter pipe fitting DIN 11864

ADAPT DIN11864-1A-BS/DN40

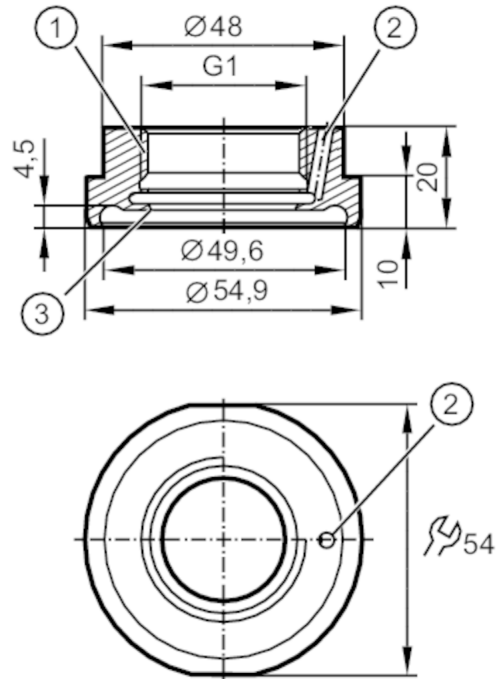

- 1 Aseptoflex Vario
- 2 Leakage port
- 3 sealing area



EC 1935/2004 EHEDG Certified



## Application

Design	with leakage port
Pressure rating [bar]	25

## Tests / approvals

Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
Safety instructions	The compatibility between medium and product material has to be checked in all applications.

## Mechanical data

Weight [g]	202
Materials (wetted parts)	stainless steel (1.4435 / 316L) ; surface characteristics : Ra<0,4 / Rz 4
Sensor connection	G 1 internal thread Aseptoflex Vario
Process connection	Pipe fitting DN40 DIN 11864-1-A-BS
Sealing	Gasket
Hygienic equipment class to DIN 11866	H4

## Accessories

Items supplied	O-ring: 1 x 24 x 2, EPDM, FDA compliant, E30054
Accessories (optional)	O-ring: 1 x 24 x 2, FKM, FDA compliant, E30123
	sealing ring: 1, PEEK, FDA compliant, E30124

## Remarks

Pack quantity	1 pcs.
---------------	--------