


AC1150



AS-Interface module for frequency inverter

2DI RS485 SEW CCT

phase-out article

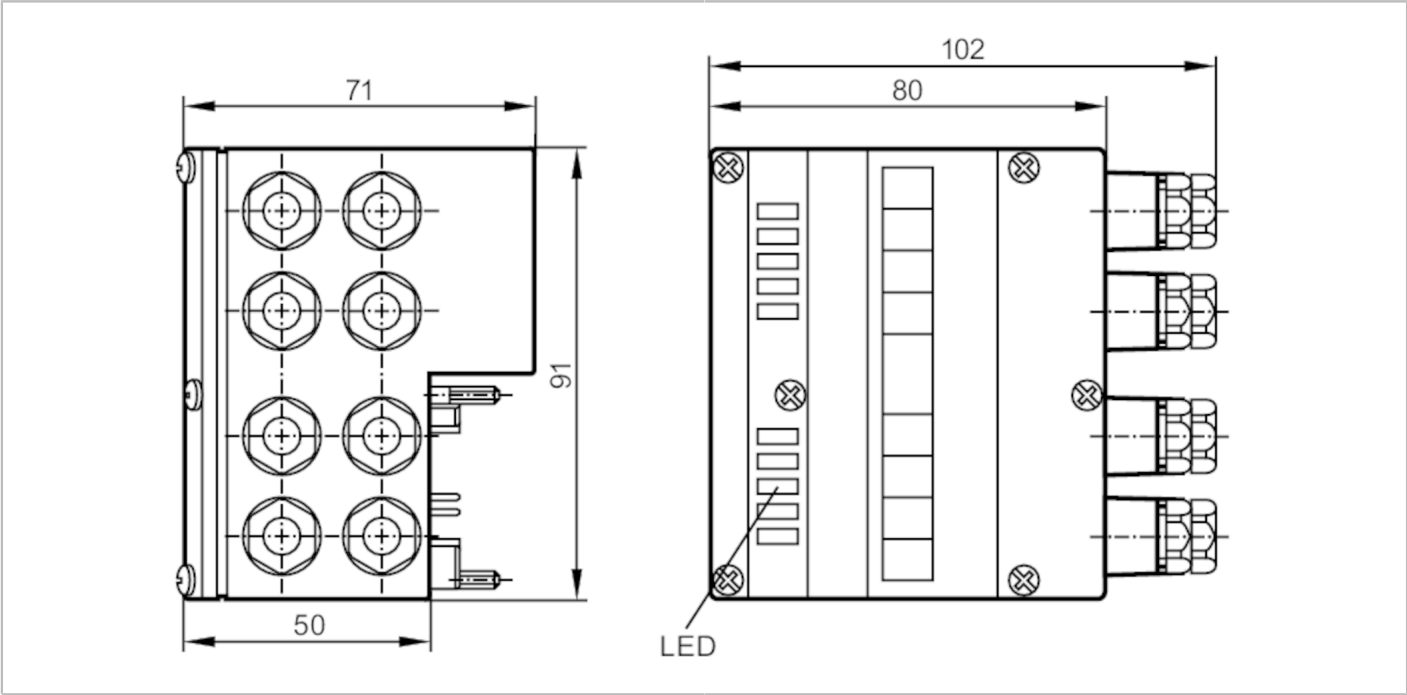

Application		
Application		field installation
Electrical data		
Operating voltage	[V]	26.5...31.6 DC
Max. current consumption from AS-i	[mA]	80
Reverse polarity protection		yes
Inputs / outputs		
Number of inputs and outputs		Number of digital inputs: 2
Inputs		
Number of digital inputs		2
Input circuit of digital inputs		PNP
Sensor supply of the inputs		AUX
Power supply	[V]	20...30
Max. total current rating of inputs	[mA]	26
Input current High	[mA]	> 5
Input current Low	[mA]	< 1
Operating conditions		
Ambient temperature	[°C]	0...55
Protection		IP 65
Tests / approvals		
EMC	EN 50295	

AC1150



AS-Interface module for frequency inverter

2DI RS485 SEW CCT

AS-i classification					
AS-i master profile	M2; M3; M4				
AS-i profile	S-7.F				
AS-i I/O configuration	[hex]	7			
AS-i ID code	[hex]	F			
Assignment of the data bits	data bit	D0	D1	D2	D3
	function	motor stopped/ running	error message	input 1	input 2
Mechanical data					
Weight	[g]	286.7			
Type of mounting	AS-i interface to FC-E lower parts				
Materials	PBT				
Displays / operating elements					
Display	switching status		LED, yellow		
	operation		LED, green		
	short circuit		LED, red		
	function		LED, red		
Remarks					
Pack quantity	1 pcs.				
Electrical connection					
contact pins to module lower part, FK-E:					