




AS-Interface module

Moduloberteil aktiv, 2x2E 200m

Article no longer available - archive entry

Alternative article: AC5215 When selecting an alternative article and accessories please note that technical data may differ! – When selecting an alternative article and accessories please note that technical data may differ!

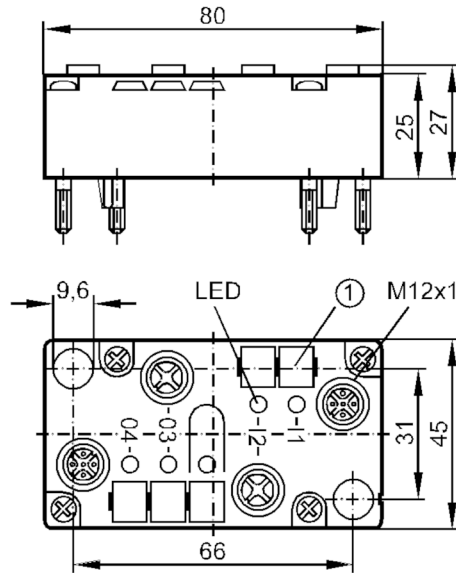

1 panel for labelling



Electrical data

Operating voltage	[V]	26.5...31.6 DC
Current consumption	[mA]	< 235

Inputs / outputs

Number of inputs and outputs	Number of digital inputs: 4
------------------------------	-----------------------------

Inputs

Number of digital inputs	4; (2 x 2)
Input circuit of digital inputs	PNP
Sensor supply of the inputs	AS-i
Voltage supply	[V] 20...30
Max. total current rating of inputs	[mA] 200
Input current High	[mA] > 5
Input current Low	[mA] < 1.5
Min. switching level high signal	[V] 10
Digital inputs protected against short circuits	yes

Outputs


Electrical design	AS-i
-------------------	------

AC2016



AS-Interface module

Moduloberteil aktiv, 2x2E 200m

Operating conditions					
Ambient temperature	[°C]	-25...85			
Protection		IP 67			
Tests / approvals					
EMC		EN 50295			
AS-i classification					
AS-i profile		S-0.1			
AS-i I/O configuration	[hex]	0			
AS-i ID code	[hex]	1			
AS-i certificate		01302			
Assignment of the data bits	data bit	D0	D1	D2	D3
	socket	I-1/2	I-1/2	I-3/4	I-3/4
	pin	4	2	4	2
Mechanical data					
Type of mounting		AS-i interface to FC lower parts			
Materials		PBT			
Displays / operating elements					
Display	operation	LED, green			
	function	LED, yellow			
Remarks					
Pack quantity		1 pcs.			
Electrical connection					
contact pins to module lower part, FK / PG:					
Connector: M12					
					

Article no longer available - archive entry

Alternative article: AC5215 When selecting an alternative article and accessories please note that technical data may differ! – When selecting an alternative article and accessories please note that technical data may differ!